


1646550 DSBG-40-80-PPVA-N3 standards-based cylinder - Series till 07-2014

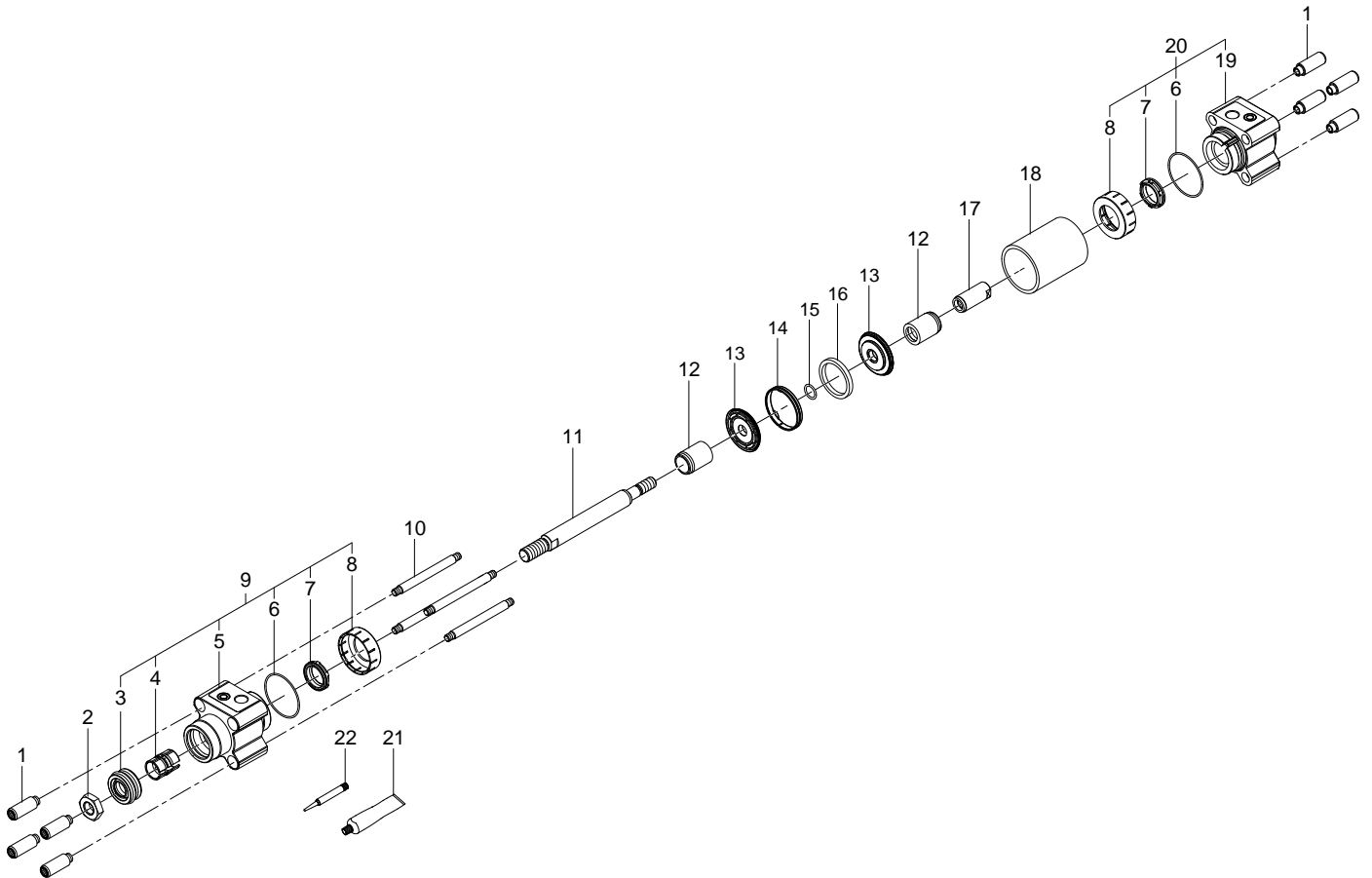

1646550 DSBG-40-80-PPVA-N3 standards-based cylinder - Series till 07-2014

Pos.	Part no.	Type	Note	Qty.	Unit
A	753089	DSBC/G- 40- - Set of wearing parts	Spare parts: 3, 6, 7, 8, 13, 14, 15, 21, 22 Replacing the wearing parts	1	PC
1	1279716	DSBG-32/40 Collar nut	Tightening torque 4 Nm / 3.0 lbf ft Use locking compound. See position 22	8	PC
2	203968	DIN 439-B-M12X1,25-04 Hex nut		1	PC
3	232275	WIFC2-16X26X10,7-TPE-U Wiper seal	Grease using during assembly. See position 21	1	PC
4	1113784	DSBX-40 Bearing		1	PC
5		DSBX-40-PPV:CO Bearing cap	Not available separately, see position 9	1	PC
6		B-40X1,2-N-NBR75 O-ring ISO3601	Not available separately, see position 9+20+999 Grease using during assembly. See position 21	2	PC
7		DIFC1-20X28X7,8-TPE-U Buffer seal	Not available separately, see position 9+20+999 Grease using during assembly. See position 21	2	PC
8		DSBX-40 Holding disc	Not available separately, see position 9+20+999	2	PC
9	1261894	DSBC/G-40-PPV Bearing cap module		1	PC
10	1374233	DSBG-40- Tie rod	When ordering please specify the stroke (see type plate)	4	PC
11	753075	DSBG-YP-40- - Piston rod	When ordering please specify the configuration (see type plate)	1	PC
12	332088	40-PPV Buffer sleeve		2	PC
13		BA-K01D-040 Piston module	Not available separately, see position A	2	PC
14		BA-K01F-040 Guiding band	Not available separately, see position A	1	PC
15		B-9,5X1,5-N-NBR70 O-ring ISO3601	Not available separately, see position A Grease using during assembly. See position 21	1	PC
16	675529	36,9X30,4X4BA-K01M-040LP Ring magnet		1	PC
17	709362	M10X1.25-D40 Threaded coupling	Tightening torque 20 Nm / 14.8 lbf ft Use locking compound. See position 22	1	PC
18		DSBG-40- Cylinder barrel	Not available Grease using during assembly. See position 21	1	PC
19		DSBX-40-PPV:CO End cap	Not available separately, see position 20	1	PC
20	1283919	DSBC/G-40-PPV End cap module		1	PC
21	684474	LUB-KC1 SILIKONFREI 20ML Lubricating grease		1	PC
22	8181256	CYBERBOND TM44 TB1ML Adhesive bonding agent		1	PC