

CARACTERÍSTICAS

- Construcción de tornillo de banco de hierro fundido
- Mordazas de acero
- cabezal de tornillo de banco giratorio de 360°
- Fijación de abrazadera G.

Torno de banco RS Pro 30mm 65mm x 60mm, 2,1 kg

Código RS: 752-2428



Los productos con aprobación profesional RS le proporcionan piezas de calidad profesional en todas las categorías de productos. Nuestra gama de productos ha sido probada por ingenieros y proporciona una calidad comparable a las marcas líderes sin pagar un precio superior.

Descripción del

RS Pro presenta este banco de trabajo ligero ideal para aplicaciones de uso general y montado en una plataforma giratoria para un ajuste de 360°. Fabricado en hierro fundido de alta calidad, este banco tiene una abrazadera en G ajustable para fijar en superficies. Esta sencilla acción de fijación significa que el tornillo de banco es muy portátil y versátil. La base fija y las mordazas de sujeción fuertes permiten una total confianza en aplicaciones profesionales.

Especificaciones

Tipo de torno	Mordaza G-Clamp
Aplicaciones	Carpinteros y carpinteros, ingenieros y metalúrgicos, mecánicos, aficionados y entusiastas

Especificaciones mecánicas

Apertura de mordaza	60mm
Ancho de mordaza	65mm
Profundidad de mordaza	30mm
Capacidad de altura de mordaza	30mm
Cabezal de torno giratorio	360°
Montaje	Abrazadera
Peso	2.1Kg




Order Code	Manufacturers Code	Description
752-2428	52-192-875	G-Clamp Vice

	Maximum Jaw Opening	60mm
	Jaw Width	65mm
	Jaw Height	30mm
	Maximum Table Clamping	40mm
	Rotating Vice Head	360°
	Flat Anvil Size	30 x 40mm
	Vice Head Material	Cast Iron
	Table Clamp Material	Cast Iron
	Vice Guide Rods	Steel
	Vice Jaw Material	Steel
	Weight	2.1K
1	Vice Jaws	
2	Vice Handle	
3	Swivelling Vice Head	
4	Table / Bench Clamp Bracket	
5	Clamp Screw	
6	Swivel Lock	
7	Flat Anvil	



This lightweight portable mini vice is suitable for use in engineering, automotive and home workshops and can be easily mounted to any convenient working surface

Maximum Jaw Opening	60mm
Jaw Width	65mm
Jaw Height	30mm
Maximum Table Clamping	40mm
Rotating Vice Head	360°

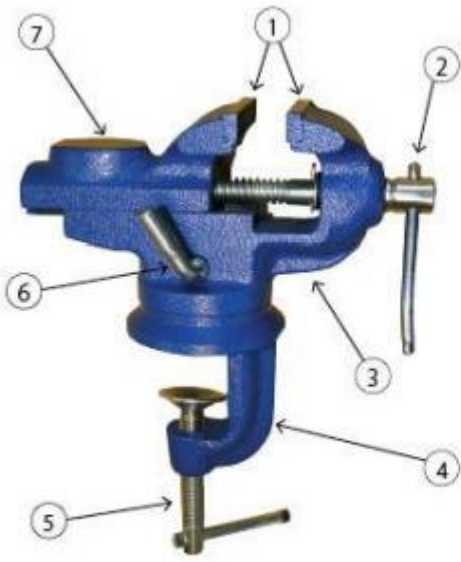

Maximum Jaw Opening	60mm
Jaw Width	65mm
Jaw Height	30mm
Maximum Table Clamping	40mm
Rotating Vice Head	360°
Flat Anvil Size	30 x 40mm
Vice Head Material	Cast Iron
Table Clamp Material	Cast Iron
Vice Guide Rods	Steel
Vice Jaw Material	Steel
Weight	2.1K

1	Vice Jaws
2	Vice Handle
3	Swivelling Vice Head
4	Table / Bench Clamp Bracket
5	Clamp Screw
6	Swivel Lock
7	Flat Anvil