


RS Stock No Colour
 423-605 Black
 423-611 Red

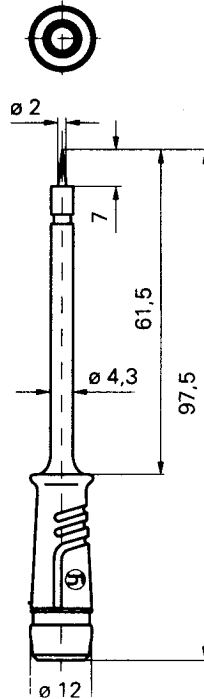

Description

Test probe with elastic shatter-proof insulated sleeve. Both insulating layers and backing layers on printed circuit boards can be penetrated by the slim stainless steel tip (7 mm, bright metal). **4 mm dia. socket connection** made of brass.

Technical data

Type of connection/ Connector	ø 4 mm	
Test probe	rigid	
Volume resistance (max.)	50 mΩ	
Permissible temperature range	-25 °C . . . +80 °C	
Colour index*	black	-100
	red	-101