


suction cup ESS-20X60-ON

Part number: 189416

FESTO

easily interchangeable,

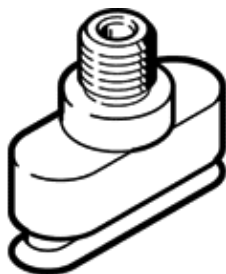

Data sheet

Feature	Value
Nominal size	6 mm
suction cup size	20x60 mm
suction cup volume	3.69 cm ³
Position of connection	on top
Assembly position	Any
Correlation to suction-cup holder	Size 5
Suction cup shape	Oval, flat
Operating pressure	0 ... 0.95 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
Corrosion resistance classification CRC	1 - Low corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	-10 ... 70 °C
Retention force at nominal operating pressure	62.8 N
Horizontal lateral force at nominal operating pressure	116 N
Vertical lateral force at nominal operating pressure	63 N
Product weight	30.8 g
Mounting type	Via vacuum port
Vacuum connection	M10
Colour	Black
Shore hardness	50 +/- 5
Materials note	Free of copper and PTFE Conforms to RoHS
Material suction cup	NBR