
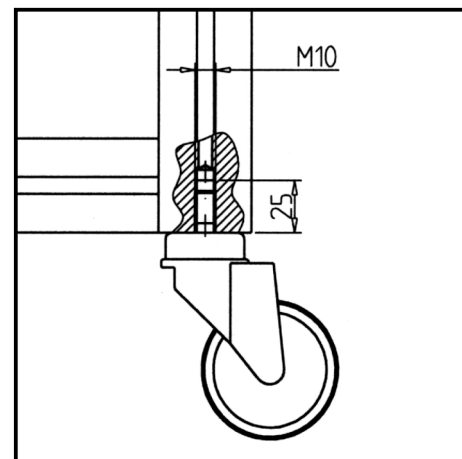
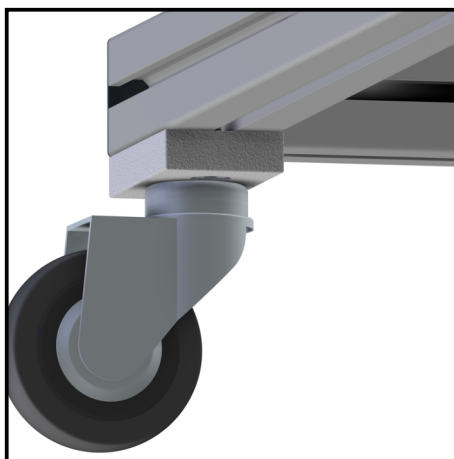


SWIVEL CASTOR WITHOUT BRAKE D 75 X 100

Article Nr. 21.1118/0

[See the product on the website →](#)

[Download CAD Files →](#)

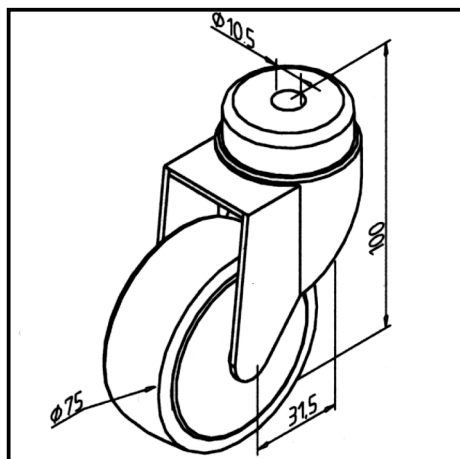

TECHN. DATA / ITEMS SUPPLIED

- Steel, galvanized
- Tire, rubber, grey
- With fastening material steel, zinc plated
- Load capacity 50 kg
- **Other versions upon request**
- Weight = 0.372 kg/piece

APPLICATIONS

- Movable tables
- Work stands
- Display windows, showcases

ASSEMBLY

- Attach directly to the central bore of the vertical profile with fastening material, then drill and introduce thread M10
- A connection plate is required if the roller is to be positioned centrally with profile cross sections 45 x 90 or 90 x 90