


Datasheet

RS Pro 12 Way Non-Fused Terminal Block With Wire Protector

RS Stock No: 464-9744

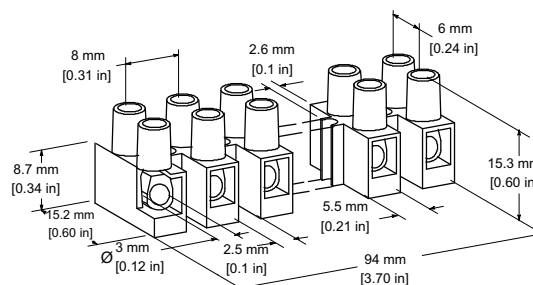

Specifications:

Housing material: Polyamid (PA 6.6) natural colour

Self-extinguishing: UL 94 V-2; IEC 695-2-1 to 850°C and IEC 695-2-2

Ambient temperature of use: 125°C

Short-time temperature: 160°C

Nominal section: 2.5 mm²

Rated voltage: 250/380 V

Test voltage: 2500 V

 
Test current: 24 A

Clamps: Nickered brass

Screws: Galvanized steel M3 x 5mm

WIRE PROTECTION VERSION: inox steel

ACCORDING NORMS: EN 60998-1: 2004, EN 60998-2-1: 2004



Wire protectors are metallic strips that physically isolate the conductor from the terminal screw. The protectors prevent cutting or nicking softer conductors.

◆ EN 60335-1: 2002 + A2: 2006 (S.C. 30.2.3)
IEC/EN 60695-2-11