


## Features

- **Material:** Nylon 66
- **Color:** Natural (
- **Flame Retardant Rating:** UL94V-2
- **Operating Temperature Range:** Up to 85°C (185°F)

## RS PRO Cable Ties

RS Stock No.: 0603222

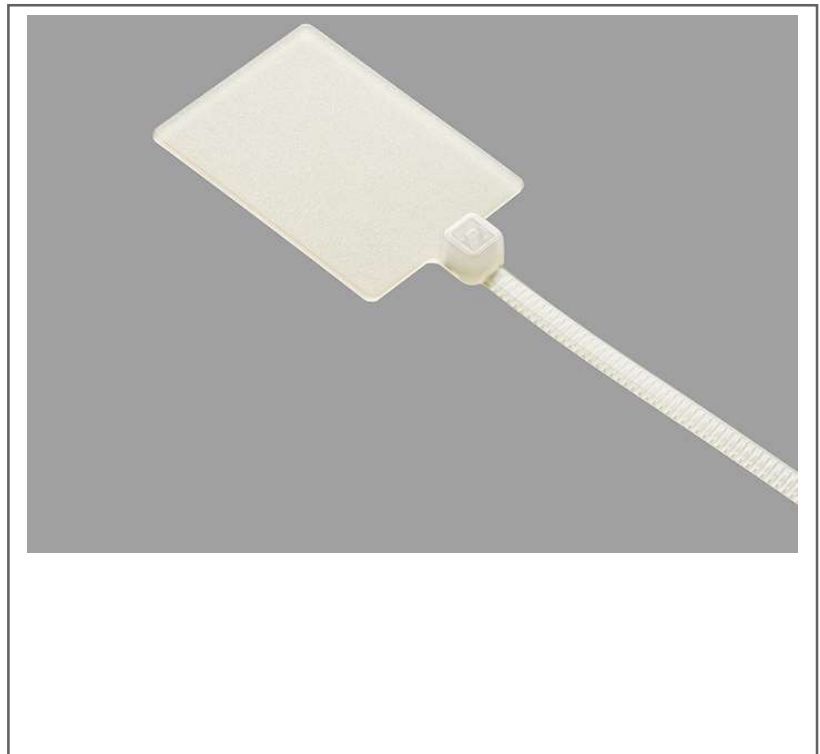

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

Simplify your cable management and identification needs with a high-quality cable tie designed to provide secure bundling and easy labelling in one efficient solution.

#### Key Features

- **Integrated Label Design:** Includes a writable label for clear identification of cables, wires, or bundled components.
- **Durable Construction:** Made from Polyamide (Nylon 66), ensuring strength, flexibility, and longevity.
- **Heat Resistance:** Operates effectively in temperatures up to 85°C (185°F).
- **Flame Retardant:** Rated UL94V-2 for safety and reliability in various environments.
- **Natural Colour:** Clean, professional appearance in white that complements most setups.

#### General Specifications

|                               |                                                     |
|-------------------------------|-----------------------------------------------------|
| Series                        | Marker Ties                                         |
| Type                          | Non-Releasable                                      |
| Colour                        | Natural                                             |
| Material                      | Nylon 66                                            |
| Finish                        | N/A                                                 |
| Application                   | Bundling wire together / Tightening labels to poles |
| UV Resistant                  | No                                                  |
| Minimum Operating Temperature | -28°C                                               |
| Maximum Operating Temperature | 85°C                                                |
| Fire Behaviour                | Self-Extinguishing                                  |
| Quantity                      | 100                                                 |

#### Mechanical Specifications

|                         |                  |
|-------------------------|------------------|
| Length                  | 130mm (75mm tie) |
| Width                   | 2.5mm            |
| Tensile Strength        | 80N              |
| Maximum Bundle Diameter | 22mm             |