

Window Kits

Bulletin
A80W, A80SW

Type 4 and 4X Deep-Hinged Window Kits



Deep-hinged window kits provide protection, visibility, and easy access to equipment and components installed behind the viewing area. Window kits are conveniently sized to allow direct mounting in the usable door area of any Hoffman enclosure with a suitably sized mounting surface. These kits have an aesthetic appearance, quarter-turn latching for easy access, .25 inch thick clear polycarbonate material for viewing, 2.5 in. (64mm) of depth to allow for deep controls, and a built-in gasket compression stop to facilitate flush mounting. Each kit comes with a mounting

template and hardware to allow for easy installation and can be mounted either left or right hand hinged. Manufactured from Type 316L stainless steel with a smooth #4 brushed finish or mild steel finished with ANSI 61 gray polyester powder paint inside and out.

Industry Standards

STAINLESS STEEL

UL 508A File No. E61997: Type 3R, Type 4, Type 4X, and Type 12
cUL CSA C22.2, No. 94, File No. E61997: Type 3R, Type 4, Type 4X, and Type 12

IP66

MILD STEEL

UL 508A File No. E61997: Type 4 and Type 12
cUL CSA C22.2 No. 94, File No. E61997: Type 4 and Type 12


Optional Handles

CWHNL - Nonlocking


CWHK - Keylocking

CWHPTO - Padlocking

Bezels Fixed and Hinged

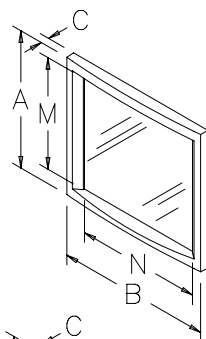

Aesthetic die-cast aluminum frames accept blank front plates (order front plate separately). Hinged bezel has a single-point slotted latch (optional locking or non-locking wing knob latch is also available). U.S. Patent pending.

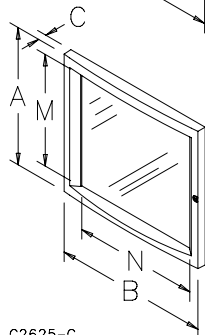

Optional Wing Knob Latches

CWKL - Locking

CWKN - Nonlocking

C2625-C

Standard Sizes Type 4 and 4X Deep-Hinged Window Kits

Catalog Number	AxBxC	Material	Window Size M x N (in.)	Window Size M x N (mm)
AWDH1418N4	12.19x14.56x2.73 (310x370x69)	Steel	8.93 x 9.86	227 x 250
AWDH1418N4SS	12.19x14.56x2.73 (310x370x69)	316L Stainless steel	8.93 x 9.86	227 x 250
AWDH1612N4	14.19x8.14x2.73 (360x207x69)	Steel	10.91 x 3.39	277 x 66
AWDH1612N4SS	14.19x8.14x2.73 (360x207x69)	316L Stainless steel	10.91 x 3.39	277 x 66
AWDH2016N4	18.19x12.14x2.73 (462x308x69)	Steel	15.60 x 8.08	396 x 205
AWDH2016N4SS	18.19x12.14x2.73 (462x308x69)	316L Stainless steel	15.60 x 8.08	396 x 205
AWDH2416N4	22.19x12.14x2.73 (563x308x69)	Steel	19.60 x 8.08	498 x 205
AWDH2416N4SS	22.19x12.14x2.73 (563x308x69)	316L Stainless steel	19.60 x 8.08	498 x 205
AWDH2420N4	22.19x16.14x2.73 (563x410x69)	Steel	19.60 x 12.08	498 x 307
AWDH2420N4SS	22.19x16.14x2.73 (563x410x69)	316L Stainless steel	19.60 x 12.08	498 x 307
AWDH2430N4	22.19x26.14x2.73 (563x664x69)	Steel	19.60 x 20.89	498 x 531
AWDH2430N4SS	22.19x26.14x2.73 (563x664x69)	316L Stainless steel	19.60 x 20.89	498 x 531
AWDH3024N4	28.19x20.14x2.73 (716x512x69)	Steel	25.60 x 14.89	650 x 378
AWDH3024N4SS	28.19x20.14x2.73 (716x512x69)	316L Stainless steel	25.60 x 14.89	650 x 378
AWDH3624N4	34.19x20.14x2.73 (868x512x69)	Steel	31.60 x 14.89	803 x 378
AWDH3624N4SS	34.19x20.14x2.73 (868x512x69)	316L Stainless steel	31.60 x 14.89	803 x 378

Accessories

Catalog Number	Catalog Number	A x B x C in. (mm)	Description	Opening Size M x N in. (mm)	Fits Enclosure (mm)
ANSI 61	RAL 7035				
CBF3136	CBF3136LG	12.2 x 14.17 x 1.26 (310 x 360 x 32)	Fixed Bezel	9.96 x 10.86 253 x 276	310 x 360 x 130
CBF4045	CBF4045LG	15.75 x 17.72 x 1.3 (400 x 450 x 33)	Fixed Bezel	13.50 x 14.40 343 x 366	400 x 450 x 150
CBF5557	CBF5557LG	21.65 x 22.44 x 1.42 (550 x 570 x 36)	Fixed Bezel	19.40 x 19.13 493 x 486	550 x 570 x 150 and 550 x 570
CBH3136	CBH3136LG	12.2 x 14.17 x 1.34 (310 x 360 x 34)	Hinged bezel	9.96 x 10.86 253 x 276	310 x 360 x 130
CBH4045	CBH4045LG	15.75 x 17.72 x 1.38 (400 x 450 x 35)	Hinged bezel	13.50 x 14.40 343 x 366	400 x 450 x 150
CBH5557	CBH5557LG	21.65 x 22.44 x 1.5 (550 x 570 x 38)	Hinged bezel	19.40 x 19.13 493 x 486	550 x 570 x 150 and 550 x 570