


1646713 DSBG-50-100-PPVA-N3 standards-based cylinder - Series: All

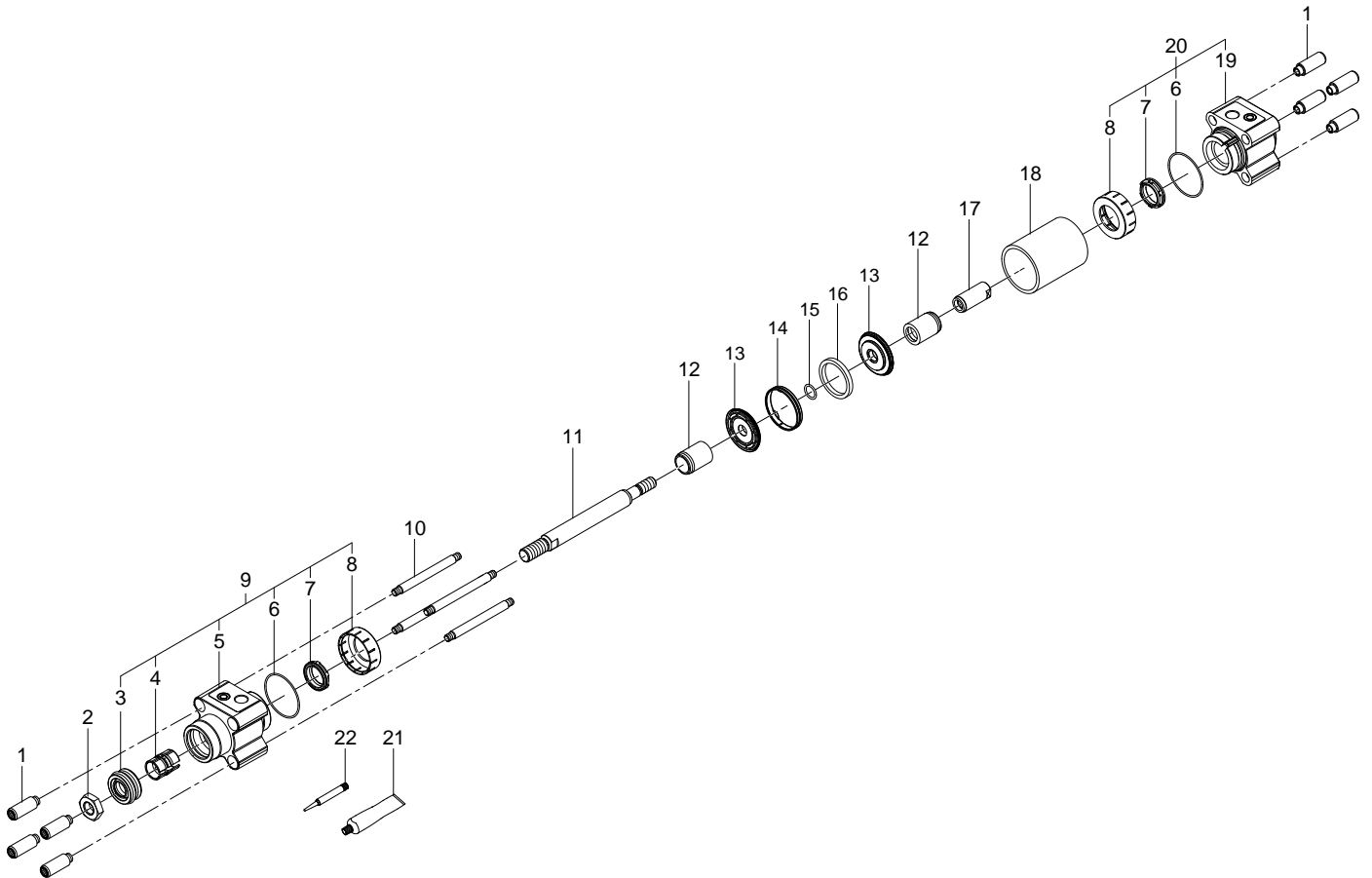

1646713 DSBG-50-100-PPVA-N3 standards-based cylinder - Series: All

Pos.	Part no.	Type	Note	Qty.	Unit
A	753090	DSBC/G- 50- - Set of wearing parts	Spare parts: 3, 6, 7, 8, 13, 14, 15, 21, 22 Replacing the wearing parts	1	PC
1	1279717	DSBG-50/63 Collar nut	Tightening torque 7 Nm / 5.2 lbf ft Use locking compound. See position 22	8	PC
2	200127	DIN 439-B-M16X1,5-04 Hex nut		1	PC
3	229860	WIFC2-20X30X10,7-TPE-U Wiper seal	Grease using during assembly. See position 21	1	PC
4	4402008	DSBX-50/63 Bearing	Grease using during assembly. See position 21	1	PC
5		DSBX-50-PPV:CO Bearing cap	Not available separately, see position 9	1	PC
6		B-50X1,2-N-NBR70 O-ring ISO3601	Not available separately, see position 9+20+999 Grease using during assembly. See position 21	2	PC
7		DIFC1-25X33X7,8-TPE-U Buffer seal	Not available separately, see position 9+20+999 Grease using during assembly. See position 21	2	PC
8		DSBX-50 Holding disc	Not available separately, see position 9+20+999	2	PC
9	1261950	DSBC/G-50-PPV Bearing cap module		1	PC
10	1379151	DSBG-50- Tie rod	When ordering please specify the stroke (see type plate)	4	PC
11	753076	DSBG-YP-50- - Piston rod	When ordering please specify the configuration (see type plate)	1	PC
12	332089	50/63 PPV Buffer sleeve		2	PC
13		BA-K01D-050 Piston module	Not available separately, see position A	2	PC
14		BA-K01F-050 Guiding band	Not available separately, see position A	1	PC
15		B-11,5X1,5-N-NBR75 O-ring ISO3601	Not available separately, see position A Grease using during assembly. See position 21	1	PC
16	358739	46,6X38,2X4,6BA-K01M-050 Ring magnet		1	PC
17	712745	M12X1.25-D50/63 Threaded coupling	Tightening torque 30 Nm / 22.1 lbf ft Use locking compound. See position 22	1	PC
18		DSBG-50- Cylinder barrel	Not available Grease using during assembly. See position 21	1	PC
19		DSBX-50-PPV:CO End cap	Not available separately, see position 20	1	PC
20	1297485	DSBC/G-50-PPV End cap module		1	PC
21	684474	LUB-KC1 SILIKONFREI 20ML Lubricating grease		1	PC
22	8181256	CYBERBOND TM44 TB1ML Adhesive bonding agent		1	PC