



808


ANTIPERL ECO

ANTI-ADHESIVE WELDING MMA AND MIG/MAG

AQUEOUS BASE - BIODEGRADABLE

BENEFITS

- Removes the adhesion of scrapings on the entire treated surface, prevents burring.
- Does not include gas in welds.
- Does not contain silicones, easily removed with water.
- All surfactants present in the formulation have a primary biodegradability of at least 80%.
- Compatible with surface treatments and paints.
- Inflammable, sans COV.
- Does not release phosgene during hot decomposition of its constituents.
- Protection anti-corrosion.
- Its versatility means that it is also recommended and used as DEMOULANT.

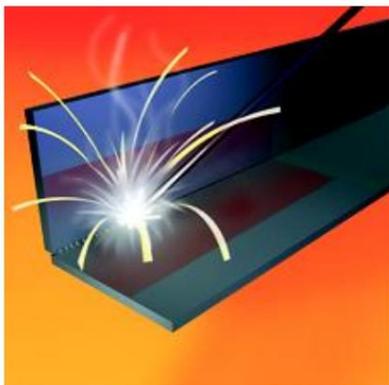

22-0082



72100354

DEFINITION

Anti-stick product for solder scrapings.

ANTIPERL ECO is a pseudo-emulsion in water of anti-adhesive products usable for the protection of assemblies and tools in arc welding operations.

Designed to respect work hygiene in welding operations where products are decomposed at high temperatures.

INSTRUCTIONS FOR USE

Apply before welding, using small sprays in a thin, even layer, holding the aerosol (or spray system) approximately 30 cm from the surface to be protected from splashes.

Make a very light deposit.

Our products are highly concentrated so a very small amount is enough to be effective.

Too much removal could interfere with your post-operations.

Apply by spraying on the parts to be treated and remove with water or a cloth.

More extensive water cleaning is required in cases of further processing.

Depending on use, can be diluted in water: 3 parts product / 1 part water.

FEATURES

Color : Blanc

Basic solvent: Water

Flash point: None

Surface wetting: Excellent

Operating temperature: 0°C +230°C

Contains no chlorine, sulfur, fluorine or silicone.

ORAPI® cannot be aware of all the applications in which its products are used and the conditions of their use. ORAPI® assumes no responsibility for: the suitability of its products for a given use or for a particular purpose, the application methods over which it has no control. The information contained in this technical data sheet must in no case replace the preliminary tests that must be carried out to verify the suitability of the product for each intended application. The user of the product described in this technical data sheet remains solely responsible for all measures required to protect people and property against all risks that may result from the implementation and/or use of this product. Consequently, ORAPI® disclaims all implied or explicit warranties, including warranties relating to the fitness for sale or suitability for a particular need, resulting from the sale or use of its products. ORAPI® specifically denies any prosecution for incidental or consequential damages of any kind, including financial operating losses.



808

ANTIPERL ECO

ANTI-ADHESIVE WELDING
MMA AND MIG/MAG
AQUEOUS BASE - BIODEGRADABLE

FIELD OF APPLICATION

General purpose anti-stick product in the welding industry.

Also usable in sectors requiring a PMUC product, without halogens (chlorine, sulfur, fluorine).

Particularly recommended for manufacturers of metal nacelles, chassis, baskets, bicycles, cars, skips, karting, railways, mechanical welding, agricultural machinery, mechanics, boilermaking, etc.

Demolding of plastic materials, concrete, etc.

PACKAGING

200 l barrel	ref. 3808 U2	x1
60 l barrel	ref. 3808 O5	x1
20 l barrel	ref. 3808 O1	x1
Jerrican 5 l	ref. 3808 J1	x4
Aerosol 650 ml	ref.4808A4	x12
PMUC :		
Aerosol 650 ml	ref. 6808 A4	x12



ORAPI® cannot be aware of all the applications in which its products are used and the conditions of their use. ORAPI® assumes no responsibility for: the suitability of its products for a given use or for a particular purpose, the application methods over which it has no control. The information contained in this technical data sheet must in no case replace the preliminary tests that must be carried out to verify the suitability of the product for each intended application. The user of the product described in this technical data sheet remains solely responsible for all measures required to protect people and property against all risks that may result from the implementation and/or use of this product. Consequently, ORAPI® disclaims all implied or explicit warranties, including warranties relating to the fitness for sale or suitability for a particular need, resulting from the sale or use of its products. ORAPI® specifically denies any prosecution for incidental or consequential damages of any kind, including financial operating losses.