



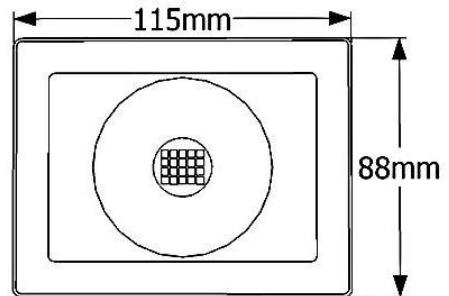

Data Specification Sheet

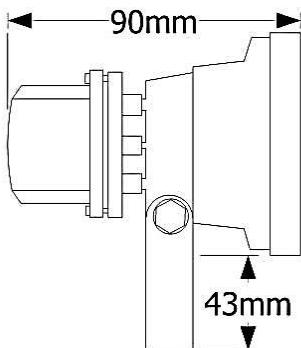

FLE10W & FLE10G 10W LED Floodlight

ML Accessories Code	FLE10W & FLE10G
Description	IP65 LED Floodlight
Base Finishes available	FLE10W – White FLE10G - Grey
Overall dimensions (mm)	See above diagram
Weight	0.58KG
Fixing	Stirrup Bracket
Typical location	Indoor or Outdoor (Not suitable for food preparation areas)
Lamp Supplied	Yes non replaceable MCOB Samsung Multi-chip
Lumen Output	750Lm
Lamp Life (Average)	30,000 Hours
Lamp Colour	6000K – Cool White
Voltage (V)	220-230V 50Hz
Wattage (W)	10W
Circuit Watts	11W
Class	Class I. Must be Earthed
IP	IP65
Photometric Testing	No
Instruction sheet	Yes
Origin of manufacture	China
Pack Included	Instructions
Main materials:	
• Body	Die-cast
• Reflector	Aluminium
• Gasket	Silicone Rubber
• Glass	Toughened 3mm glass
Lamp holder cap and make	N/A
Lamp type	MCOB Samsung Multi-Chip
Electrical Connections	Pre-wired TRS Rubber 0.5m
Dimmable	No
Distance from flammable object	1mtrs
CE mark	Yes
Quality Assurance System	Yes ISO 9001 QMS
Batch coding details	Yes
Certificate of Conformity	Yes
Manufactured in accordance	EN60 598-2-5
Guarantee Period	1 Year

ML Accessories Ltd. reserves the right to withdraw, improve or modify any design without prior notification.

ML Accessories Ltd. cannot be held responsible for the incorrect application of any product.