
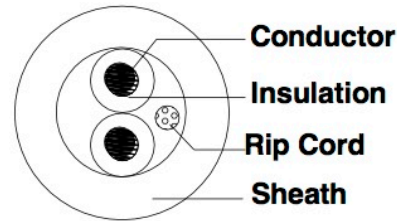


2 Core LSOH Pink Loudspeaker Cable

CABLE
POWER

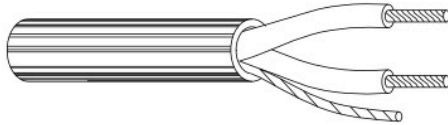

DESCRIPTION

Stranded Plain Annealed Copper Wire, 2Core, PE Insulation, Rip Cord, LSHF Sheath.

APPLICATION

For the interconnection of control equipment and instruments.

CONSTRUCTION

Conductor

Material : Stranded Plain Annealed Copper Wire

Stranding : 30/0.24mm (1.5mmsq.)

Insulation

Material : PE Compound

Nominal Thickness : 0.4mm

Nominal I.D : 2.5mm

Color : Red, White

Filler

Material : Rip Cord

Sheath

Material : LSHF

Nominal Thickness : 0.7mm

Nominal O.D : 6.6mm

Color : Pink

PHYSICAL PROPERTIES

Min. Bend Radius : 66mm

Operating Temperature : -25°C to 90°C

ELECTRICAL PROPERTIES

Max. Conductor DC resistance @ 20°C : 13.3Ω/km

Voltage test : Core to Core : 2000V a.c / 1min

APPLICABLE STANDARD

EU RoHS Complies

Part numbers:

| | |
|------|----------|
| 50m | SC-2-50 |
| 100m | SC-2-100 |
| 150m | SC-2-150 |
| 300m | SC-2-300 |