


Technical data

KH1428

Ball sleeves



VISUAL (S)

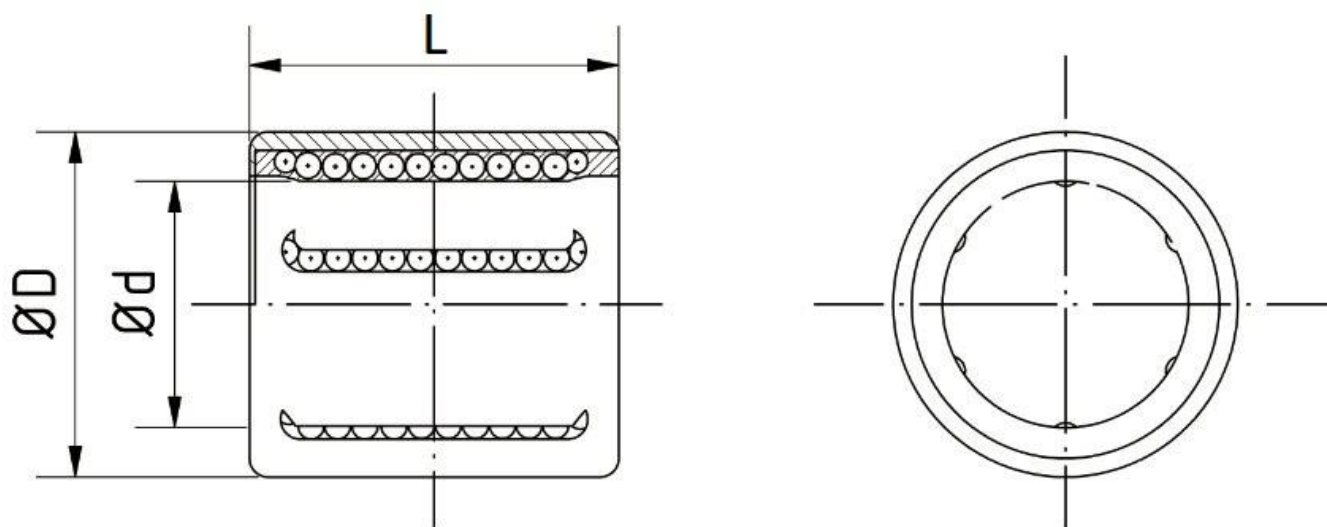

PRODUCT DEFINITION

Brand	NTN
Design type	KH
Ball bushings category	Ball sleeves
Standard	ISO dimension
Material outer cylinder or steel segments	hardened steel sleeve
Material Cage	PA
Initial greasing	Non/No
Re-lubricable	Oui/Yes
d - Internal diameter	14 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

D - External diameter	21 mm
L - Length	28 mm
Number of ball rows	5
Mass	0,021 kg

PRODUCT PERFORMANCE

Cmin	600000 mN
Cmax	600000 mN
C0min	505000 mN
C0max	505000 mN
Tmin - Min operating temperature	253,15 °K
Tmax - Max operating temperature	353,15 °K

