


## SLIM LED FLOODLIGHT ORLANDO

ORLANDO50G

50 W - 5500lm - 4000K

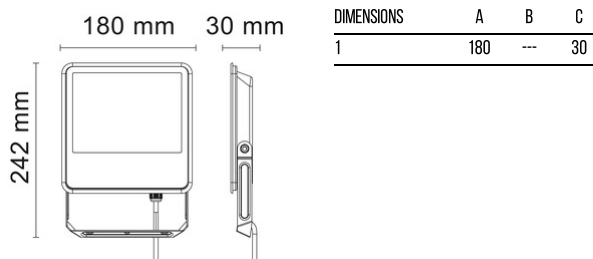

### GENERAL INFORMATIONS

|                             |                                |
|-----------------------------|--------------------------------|
| Code                        | ORLANDO50G                     |
| Ean                         | 8031453023287                  |
| Family                      | SLIM LED FLOODLIGHT<br>ORLANDO |
| Technology                  | LED                            |
| Body material               | Aluminum                       |
| Diffuser / lens material    | Glass                          |
| Operating temperature (° C) | -20 - +40                      |

### PACKAGING

|           |     |
|-----------|-----|
| Packaging | BOX |
| Pack      | 10  |

### LIGHTING DATA

|                            |      |
|----------------------------|------|
| Kelvin (°)                 | 4000 |
| Lumen                      | 5500 |
| Beam (°)                   | 100  |
| Luminous efficacy (lm / W) | 110  |
| Color rendering (CRI)      | >70  |

### TECHNICAL FEATURES

|                              |           |
|------------------------------|-----------|
| Power (W)                    | 50        |
| Supply voltage (V) / Max (V) | 220 / 240 |
| Power frequency (Hz)         | 50/60     |
| Insulation class             | 1         |
| Power factor                 | >0,9      |
| Dimmer compatibility         | NO        |

## **SLIM LED FLOODLIGHT ORLANDO**

ORLANDO50G

50W - 5500lm - 4000K

- Slim LED floodlight with 'Driver On Board' (DOB) technology
- High efficiency 110 lm / W (ORLANDO10B/G 90 lm/W)
- Painted aluminum body with tempered glass diffuser
- White RAL 9016 or grey RAL 7024 colors - PIR version only in grey RAL 7024
- ORLANDO90B/G: Integrated valve to in order to avoid condensation

