


Mod. 2437 B

2437 EXPLORER CASES

The new **Explorer Cases 2437** is a compact, basket-shaped case designed for maximum protection in demanding environments. With external dimensions of **269×304×388 mm** and internal dimensions of **240×240×370 mm**, it withstands **drops from up to 9 meters**. It features a **top carry handle**, **automatic pressure valves**, a **pull-style latch**, and a **shoulder-strap attachment point**. Available in **black, orange, and green**, it can be supplied **empty** or with **pre-cubed foam** for tailored equipment protection.



METRIC MM-KG-C°

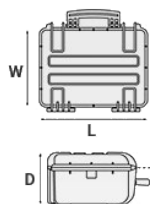**INTERNAL DIMENSIONS**

L LENGTH	240 mm
W WIDTH	240 mm
D DEPTH	370 mm
LID	70 mm
BASE	300 mm


EXTERNAL DIMENSIONS

L LENGTH	304 mm
W WIDTH	269 mm
D DEPTH	388 mm

OTHER DATA

WEIGHT EMPTY	2.45 Kg
WEIGHT WITH FOAM	2.87 Kg
WEIGHT WITH CUSTOM FOAM	Kg
VOLUME	21.3 lt
BUOYANCY	15.6 Kg/max
OPERATING TEMPERATURE	°C min -24 / max 90

IMPERIAL IN-LBS-F°

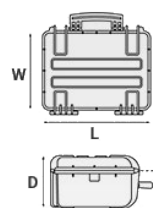

INTERNAL DIMENSIONS

L LENGTH	9.45 in
W WIDTH	9.45 in
D DEPTH	14.57 in
LID	2.76 in
BASE	11.81 in

EXTERNAL DIMENSIONS

L LENGTH	11.97 in
W WIDTH	10.59 in
D DEPTH	15.28 in

OTHER DATA

WEIGHT EMPTY	5.4 lbs
WEIGHT WITH FOAM	6.33 lbs
WEIGHT WITH CUSTOM FOAM	lbs
VOLUME	5.63 gal
BUOYANCY	34.39 lbs/max
OPERATING TEMPERATURE	°F min 11.2 / max 194