


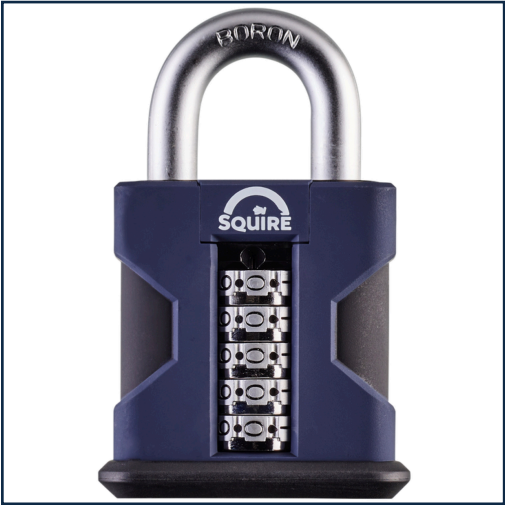

SS50 COMBI

- Heavy duty combination padlock
- 50mm wide solid hardened steel lock body
- Electrophoretic anti-corrosion finish
- Highly attack resistant
- Weather resistant protective body sleeve
- 10mm diameter boron alloy hardened steel shackle
- Available with standard shackle & closed shackle
- Fully recodable 5-wheel dial with 100,000 possible combinations
- Salt spray tested up to 200 hours
- Squire security rating: High



Product Name	Body Width	Body Thickness	Shackle Diameter	Vertical Clearance	Horizontal Clearance	Approx. Height	Approx. Weight
SS50/COMBI	55 mm	30 mm	10 mm	24 mm	22 mm	100 mm	0.54 kg
SS50C/COMBI	55 mm	30 mm	10 mm	14 mm	16 mm	95 mm	0.63 kg



SS50 COMBI

- Heavy duty combination Stronghold padlock
- 50mm wide solid hardened steel lock body
- Electrophoretic anti-corrosion finish
- Highly attack resistant
- Weather resistant protective body sleeve
- 10mm diameter boron alloy hardened steel shackle
- Available with standard shackle, long shackle & closed shackle
- Fully recodable 5-wheel dial with 100,000 possible combinations
- Salt spray tested up to 200 hours
- Squire security rating: High



Product Name	Body Width	Body Thickness	Shackle Diameter	Vertical Clearance	Horizontal Clearance	Approx. Height	Approx. Weight
SS50/COMBI	55 mm	30 mm	10 mm	24 mm	22 mm	100 mm	0.54 kg
SS50/2.5/COMBI	55 mm	30 mm	10 mm	64 mm	22 mm		
SS50C/COMBI	55 mm	30 mm	10 mm	14 mm	16 mm	95 mm	0.63 kg