


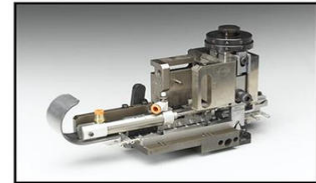

**Part Number :** [638854200](#)  
**Product Description :** Mini-Mac Applicator  
**Series Number :** 207127  
**Status :** Active  
**Product Category :** Applicators and Crimp Modules



---

## Documents & Resources

### Tooling Specifications

- [ATS-638854200-001.pdf](#)
- [TM-640160065-001.pdf](#)
- [TM-640160065CN-001.pdf](#)
- [TM-640160065DE-001.pdf](#)
- [TM-640160065SP-001.pdf](#)
- [TM-640160065FR-001.pdf](#)
- [TM-640160065IT-001.pdf](#)
- [TM-640160065JP-001.pdf](#)
- [TM-640160065KR-001.pdf](#)
- [TM-640160065MY-001.pdf](#)
- [TM-640160065PL-001.pdf](#)
- [TM-640160065RU-001.pdf](#)
- [TM-640160065SK-001.pdf](#)
- [TM-640160065TH-001.pdf](#)
- [TM-640160065VN-001.pdf](#)
- [TM-640160065TW-001.pdf](#)
- [TM-638800000-001.pdf](#)
- [TM-638800000SP-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Relevant

EU ELV	Not Relevant
Low-Halogen Status	Not Relevant
REACH SVHC	Not Relevant
EU RoHS	Not Relevant

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### Substances of Interest

- PFAS

### EU RoHS Certificate of Compliance

### Additional Product Compliance Information

## Part Details

### General

Status	Active
Category	Applicators and Crimp Modules
Series	207127
Description	Mini-Mac Applicator
Comments	The Molex Tape Applicator requires an industry standard crimp press with a 4-way air like the Molex TM-3000: 638017200, 638017300, and the Molex TM-4000: 638017600
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	toolingsupport@molex.com
Product Name	Mini-Mac
Tool Type	Applicator

UPC	822348758838
Warranty Disclaimer	<p>CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.</p>

## Mates With / Use With

### Use with Part(s)

Description	Part Number
TM-3000 Universal Crimp Press, 120AC 50/60Hz, Used for product up to 10 AWG	<u>638017200</u>
TM-3000 Universal Crimp Press, 220AC 50/60Hz, Used for product up to 10 AWG	<u>638017300</u>
TM-4000 Universal Crimp Press, 240AC 50/60Hz, Used for product up to 4 AWG	<u>638017600</u>
Use With	Most Industry Standard Presses or Wire Process Machines

---

## Applicable Parts

Description	Part Number
InsulKrimp Quick Disconnect,	<u>190030042</u>

Female, for 14-16 (2.00-1.30mm <sup>2</sup> ), Mylar Tape, Tab 6.35 x 0.81mm, Blue	
InsulKrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ), Mylar Tape, Tab 6.35 x 0.81mm	<u>190030049</u>
InsulKrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ), Mylar Tape, Tab 4.75 x 0.51mm, Blue	<u>190030052</u>
InsulKrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ), Mylar Tape, Tab 4.75 x 0.51mm	<u>190030055</u>
InsulKrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ), Mylar Tape, Tab 4.75 x 0.81mm, Aqua	<u>190030058</u>
InsulKrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ), Mylar Tape, Tab 4.75 x 0.81mm	<u>190030061</u>
InsulKrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ), Mylar Tape, Tab 5.21 x 0.51mm, Blue	<u>190030077</u>
InsulKrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ), Mylar Tape, Tab 5.21 x 0.81mm, Aqua	<u>190030078</u>
InsulKrimp Quick Disconnect, Female, Mylar Tape, Tab 4.75 x 0.51mm	<u>190030133</u>
InsulKrimp Quick Disconnect, Female, Mylar Tape, Tab 4.75 x 0.81mm	<u>190030136</u>
InsulKrimp Quick Disconnect, Female, for 14-16 (2.00-1.30mm <sup>2</sup> ) Wire, Mylar Tape, Tab 6.35 x 0.81mm	<u>190170041</u>
Quixon Quick Disconnect, InsulKrimp Style, Female, Partially Insulated Blue, 16-14 AWG, Mylar Tap	<u>192740006</u>

Quixon Quick Disconnect, InsulKrimp Style, Female, Fully Insulated Blue, 16-14 AWG, Mylar Tap	<u>192760006</u>
--	------------------