


DATASHEET



SUR5SLEMBK

230V IP20 40W LED Dual Mount Slim Line
Emergency Luminaire Matt Black

www.mlaccessories.co.uk

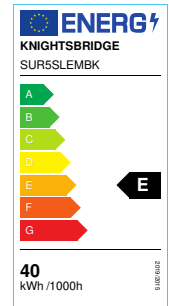

MLA PART CODE	SUR5SLEMBK
DESCRIPTION	230V IP20 40W LED Dual Mount Slim Line Emergency Luminaire Matt Black
NET WEIGHT (KG)	3.3
FINISH	Matt Black
DIFFUSER	Opal
DIMENSIONS (MM)	Length - 1500 Width - 145 Projection - 45
CONSTRUCTION	Construction - Pressed steel Construction 2 - & polypropylene
CLASS	I
IP RATING	IP20
WATTAGE (W)	40
LAMP TECHNOLOGY	SMD LED
LAMP INCLUDED	Yes
LUMENS (LM)	3010
LUMENS LIGHT SOURCE ONLY (LM)	5320
LUMEN TOLERANCE	5%
EFFICACY (LM/W)	133
LUMENS EMERGENCY MODE (LM)	165
CIRCUIT WATTAGE (W)	40
CCT	4000K
LIGHT COLOUR	Cool White
CRI	>80
SDCM	<6
RUNNING CURRENT (A)	0.18
DISPLACEMENT FACTOR	>0.9
SVM	0
PST-LM	0
BEAM ANGLE (DEGREES)	115

L70B50 LIFESPAN (HRS)	50,000
DIMMABLE	No
EMERGENCY	Maintained / Non-maintained / Switched
SELF-TEST	No
OPERATING TEMPERATURE	25°C
INPUT VOLTAGE	230V 50Hz
CABLE ENTRY (MM)	20
CABLE GLAND INCLUDED	Blind grommet
DRIVER	DRIVER TYPE - Constant Current MAX. OUTPUT - 42W OUTPUT VOLTAGE - 30-43V OUTPUT CURRENT - 960mA POWER FACTOR - 0.95 EFFICIENCY FULL LOAD - 95.0 ISOLATION - SELV AMBIENT TEMPERATURE (Ta) - -20~50°C CASE TEMPERATURE (Tc) - 75°C
BATTERY TYPE	LiFePO4
BATTERY INCLUDED	Yes
WARRANTY	5year(s)
WARRANTY INFORMATION	(excluding battery)
MANUFACTURED IN ACCORDANCE WITH	BS 60598
ORIGIN OF MANUFACTURE	China
DECLARATION OF CONFORMITY (HELD ON FILE)	Yes
EAN	5061061275290

Date Created: 26/06/2025 11:11

