

## Features

- Threaded Coupling
- IP68
- 2-5 Poles
- Cable to Cable Connections

## RS PRO SP11 In-Line Cable Mount Connector

RS Stock No.:

0304626	0304632
0304628	0304634
0304629	0304635
0304631	0304637



Image for representational purposes only

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding. Making RS PRO the Smart Choice for our customers.





## Product Description

The RS Pro SP11 series is a range of lightweight but robust waterproof connectors, which are sealed to IP68. Threaded coupling ensures a secure connection, even in the harshest environments. Plugs and receptacles are available with either male pins or female sockets. These products are ideal for use in outdoor applications where a secure, waterproof connection is required. Updated shell offering an improved seal, which increases reliability and durability.

## General Specifications

<b>Housing Material</b>	PC, Nylon66, Fire Resistance: V-0
<b>Size</b>	SP11
<b>Cable outer diameter range</b>	4-6.5mm
<b>Body Orientation</b>	Straight
<b>Colour</b>	Black
<b>Temperature Range</b>	-40~ +85°C
<b>Mounting Type</b>	In-Line Cable Mount
<b>Mating Cycle</b>	500
<b>Application</b>	Outdoor Lighting, LED Screens, Outdoor Security Cameras, and Industrial Control Systems.

## Solder Contact Options

Number of contact	2	3	4	5
Male contact face view				

## Electrical Specifications


RS Article Number	0304626	0304632	0304628	0304634
Specification	2 Pin	2 Pin	3 Pin	3 Pin
Rated Current (A)	5	5	5	5
Contact Diameter (Ø mm)	1	1	1	1
Rated Voltage (AC.V)	180	180	180	180
Test Voltage (AV.V) 1 min	1000	1000	1000	1000
Contact Resistance (m Ω)	5	5	5	5
Wire Size (mm <sup>2</sup> / AWG)	≤0.75/18	≤0.75/18	≤0.75/18	≤0.75/18
Contact Gender	Male	Female	Male	Female
Shell type	Receptacle	Receptacle	Receptacle	Receptacle
Termination	Solder	Solder	Solder	Solder

RS Article Number	0304629	0304635	0304631	0304637
Specification	4 Pin	4 Pin	5 Pin	5 Pin
Rated Current (A)	3	3	3	3
Contact Diameter (Ø mm)	0.7	0.7	0.7	0.7
Rated Voltage (AC.V)	125	125	125	125
Test Voltage (AV.V) 1 min	1000	1000	1000	1000
Contact Resistance (m Ω)	10	10	10	10
Wire Size (mm <sup>2</sup> / AWG)	≤0.5/20	≤0.5/20	≤0.5/20	≤0.5/20
Contact Gender	Male	Female	Male	Female
Shell type	Receptacle	Receptacle	Receptacle	Receptacle
Termination	Solder	Solder	Solder	Solder

## Protection Category

IP Rating	IP68
-----------	------

## Dimensional Line Drawings

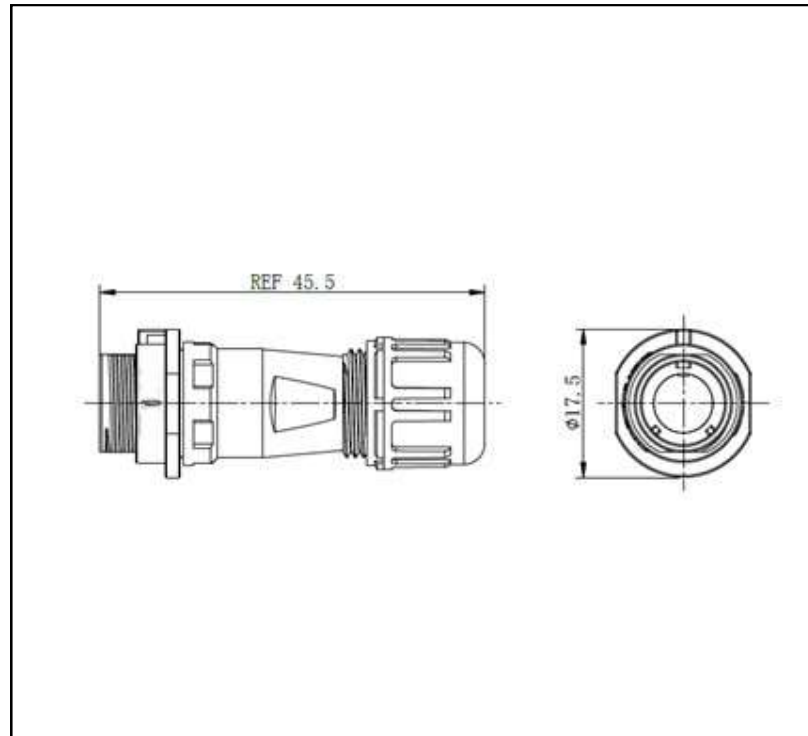

Connection Diagrams / Assembly Diagrams / Illustrations / Accessories