


SPEAKER CABLES: FHP 215 – FHP 225 – FHP 2400

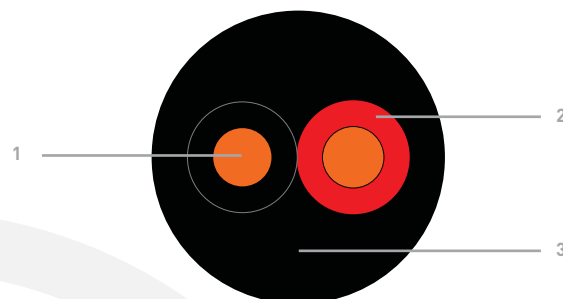

FHP225

1. Composition of core: multi-strand bare copper
 FHP215: 30 x 0,25 mm
 FHP225: 50 x 0,25 mm
 FHP2400: 127 x 0,20 mm
2. Conductor insulation: PVC
 Color coding of conductors: black, red
3. Jacket: Black PVC



APPLICATIONS

- Wiring of all types of sound systems
- Connection of amplifiers and speakers
- Wiring of fixed and mobile installations
- Public Address

PRODUCT ADVANTAGES

- Robustness
- Color coding of conductors
- Very robust
- Available in cords – ON AIR PRO range
- Flexibility

MECHANICAL CHARACTERISTICS

- Operating temperature: -20°C - + 70°C
- Bend radius: Fixed station: 5 x outer diameter
 Mobile station: 10 x outer diameter

ELECTRICAL CHARACTERISTICS

- Operating voltage: 300 v

SUITABLE PLUGS

- XLR, Jacks, Speakon

Part Nb	Nb of conductors	Section	Jacket	Outer diameter	Weight	Packaging
FHP215	2	1.50 mm ²	Black PVC	6.20 mm	60 kg / km	100 m and 500 m
FHP225	2	2.50 mm ²	Black PVC	7.40 mm	87 kg / km	100 m and 500 m
FHP2400	2	4.00 mm ²	Black PVC	10.20 mm	130 kg / km	1000 M