


Part Number: 1902X00X

Type	Size	Rating	Description
LED	M6	-	LED Prominent Panel Indicator

Dimensions (mm)

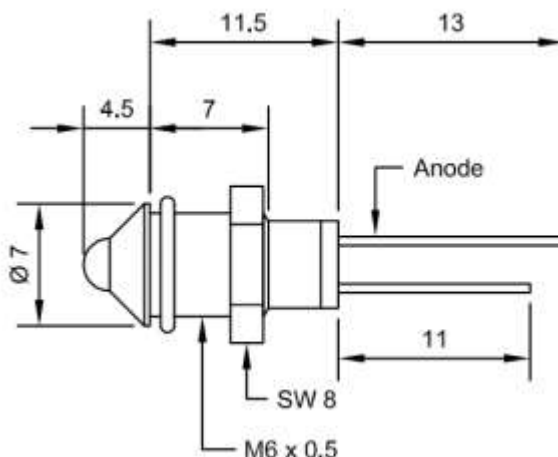

Part #	Colour	Voltage V <sub>f</sub>	Intensity (mcd@10mA)
1902X003	Red	2.0	25
1902X001	Green	2.2	20
1902X002	Yellow	2.1	15
1902X004	Red/Green	2.0/2.2	25/20
1902X005	Red/Yellow	2.0/2.1	25/15
1902X006	Green/Yellow	2.2/2.1	20/15
1902X007	Blue	3.8	30
1902X008	Orange	2.05	30
1902X00W	White	3.2	3000

Bezel types - X=0 satin chrome / X=1 black chrome / X=2 matt chrome

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 Luminous intensity at DC
- 3 Storage temperature -25 °C to +80°C
- 4 Application temperature -20 °C to +60°C
- 5 Due to component tolerances, colour temperature variations may be observed
- 6 The terminals are not qualified for soldering
- 7 Ingress rating IP40
- 8 The plastic(polycarbonate) has limited chemical resistance
- 9 RoHS & REACH SVHC compliant