


FEATURES

- **UV Resistant:** Provides durability in outdoor environments
- **Tensile Strength of 22 kg:** Ensures strong and reliable cable bundling
- **Operating Temperature Range -40°C to 85°C:** Suitable for various environmental conditions
- **Complies with RoHS and UL 94HB Standards:** Meets safety and environmental regulations
- **Maximum Bundle Diameter of 105 mm:** Accommodates large cable bundles
- **Made from Nylon:** Offers flexibility and strength

RS PRO Nylon Cable Tie, 368mm Non-Releaseable

RS Stock No: 656-098

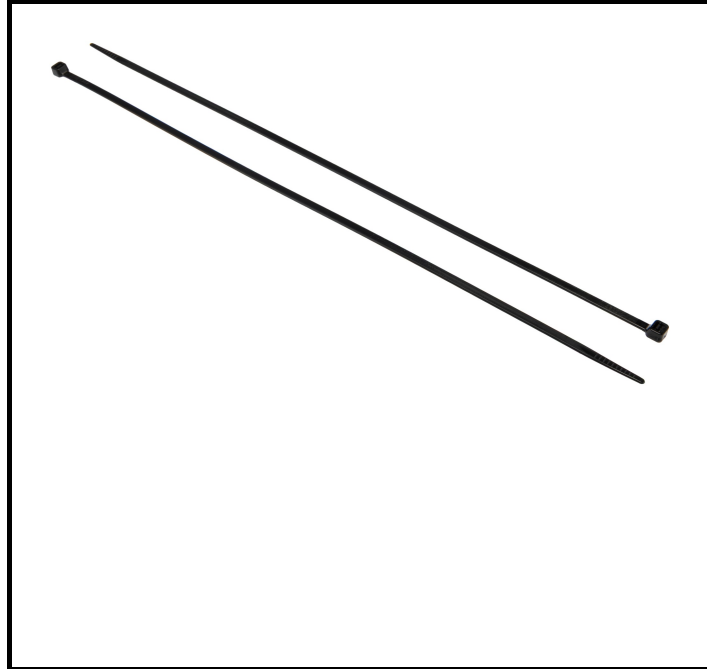

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

These RS PRO nylon cable ties are designed for securing and organising cables efficiently. With a length of 368 mm, they are ideal for bundling larger cable groups. The non-releasable design ensures a secure hold, making them suitable for permanent installations.

General Specifications

Colour	Black
Product Type	Cable Tie
Sub Type	Non-Releasable
Tensile Strength	22 kg

Protection Category

Fire Behaviour	UL 94HB
UV Resistant	Yes

Mechanical Specifications

Length	368 mm
Material	Nylon
Maximum Bundle Diameter	105 mm
Width	4.8 mm

Operation Environment Specifications

Maximum Operating Temperature	85 °C
Minimum Operating Temperature	-40 °C

Approvals

Standards/Approvals	RoHS, UL94HB
---------------------	--------------

