




LED Ecobasic Stick T37 E27 9W (61W) 820lm 827

Article number: 146330

BAI LED Ecobasic Stick T37 E27 9W (61W) 820lm 2700K 200° 37x115mm LED-lamp

Because these low-budget lamps are very durable due to their low consumption and long lifespan, they are both ECOlogical and ECONomic. This version of the Ecobasic is not dimmable. Ambient temperature range: -15°C to +40°C.

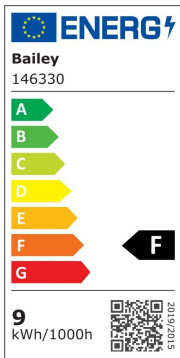

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED Ecobasic Stick T37 E27 9W (61W) 820lm 827
Brand	Bailey
Productseries	Ecobasic LED stick
Producttype	Compact

ETIM specifications

Socket	E27
Luminous flux [lm]	820 - 820
Nominal voltage [V]	220 - 240
Lamp power [W]	9 - 9
Colour temperature [K]	2700 - 2700
Diameter [mm]	37
Length [mm]	115
Dimmable	No
Lamp shape	Tube, single-ended
Beam angle [°]	200 - 200
Colour	White
Type of glass/cover	Opal
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Rated luminous flux according to IEC 62612 [lm]	820
Power factor	0.7
Lamp efficacy [lm/W]	91
Nominal current [mA]	50 - 50
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	White
Average nominal lifetime [h]	20000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	50000
Weighted energy consumption in 1000 hours [kWh]	9
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No
Material of light bulb	Plastic

Alternative articles



146342
LED Special T32x90 E27 DIM
7.3W (60W) 806lm 827