



Terminals & Splices > Terminal Housings, Insulation Sleeves & Blocks > Crimp Terminal Housings



Terminal Type: **Tab**
Connector & Housing Type: **Tab Housing**
Number of Positions: **8**
Terminal Orientation: **Straight**
UL Flammability Rating: **UL 94V-2**

Features

Product Type Features

Connector & Contact Terminates To	Wire & Cable
Sealable	No
Connector & Housing Type	Tab Housing

Configuration Features

Number of Positions	8
---------------------	---

Body Features

Connector & Keying Code	C
Primary Product Color	Natural

Contact Features

Terminal Type	Tab
Terminal Orientation	Straight
Contact Mating Retention	With

Mechanical Attachment

--	--



Mating Alignment Type	Polarization
Mating Retention Type	Locking Lance
Mating Alignment	With
Connector Mounting Type	Panel Mount

Housing Features

Housing Material	Polyamide
Centerline (Pitch)	5 mm[.196 in]

Dimensions

Product Length	33 mm[1.929 in]
----------------	-----------------

Usage Conditions

Operating Temperature Range	-40 – 105 °C[-40 – 221 °F]
-----------------------------	----------------------------

Industry Standards

UL Flammability Rating	UL 94V-2
------------------------	----------

Packaging Features

Packaging Quantity	200
--------------------	-----

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

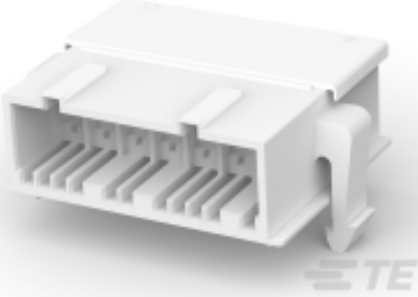
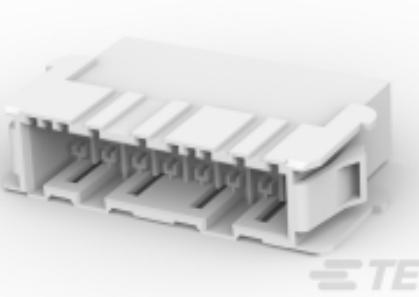
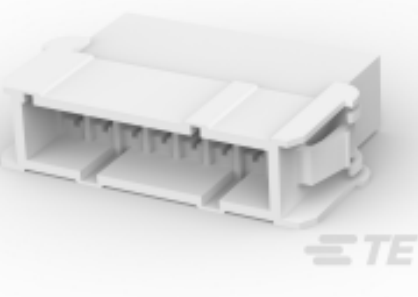
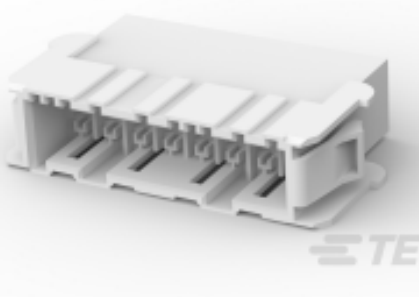
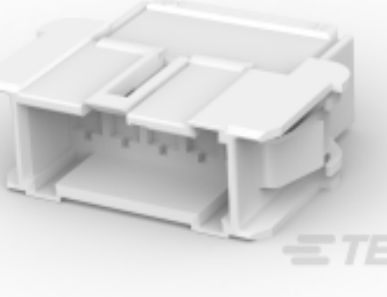
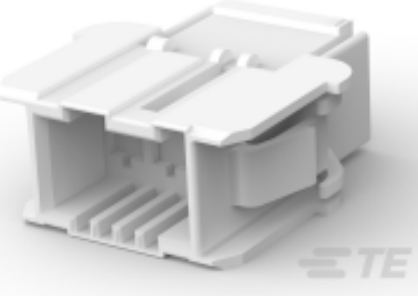
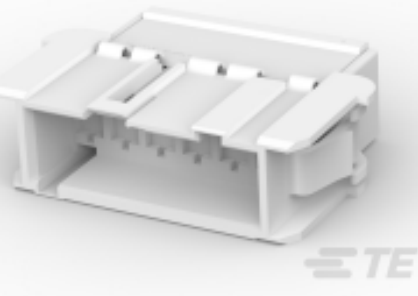
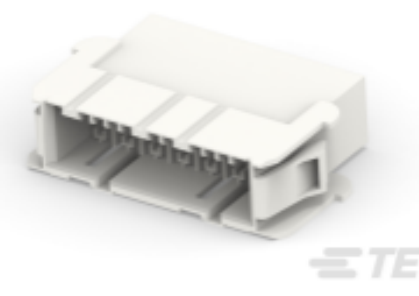
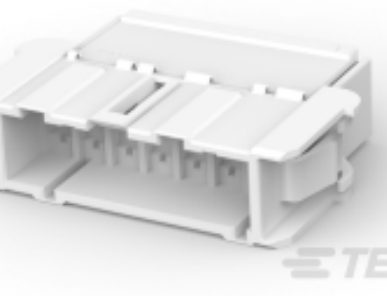
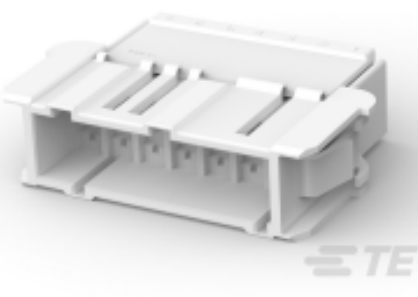
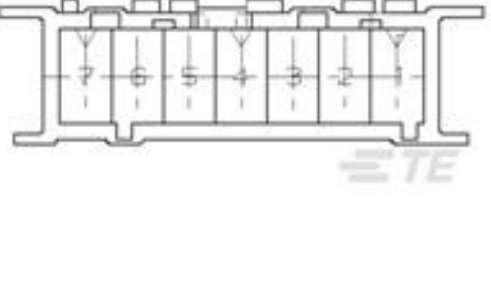
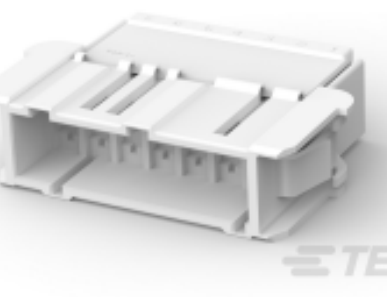
Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous



materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 TE Part # 2-293015-1 7 POS. FASTIN FASTON TAB HSG.	 TE Part # 293015-1 7 POS. FASTIN FASTON TAB HSG.	 TE Part # 1241967-8 FASTIN FASTON TAB HOUSING 8P	 TE Part # 293043-1 8POS. FASTIN-FASTON, TAB HOUSING RAST5
 TE Part # 293161-1 5 POS. FASTIN-FASTON* TAB HSG, RAST5	 TE Part # 928309-8 8P FF FLACHST GEH	 TE Part # 5-1241967-8 FASTIN FASTON TAB HOUSING 8P	 TE Part # 293011-1 5 POS. FASTIN-FASTON CONN. TAB HOUSING R
 TE Part # 293008-3 3 POS. FASTIN-FASTON CONN. TAB HOUSING R	 TE Part # 7-927742-6 6 POS. FASTIN-FASTON* TAB HSG RAST5	 TE Part # 5-1241967-7 7POS. FASTIN-FASTON* TAB HSG, RAST5	 TE Part # 284985-1 7 POS. FASTIN-FASTON CONN. TAB HSG, RAST
 TE Part # 293010-1 5 POS. FASTIN-FASTON CONN. TAB HOUSING R	 TE Part # 293034-3 7 POSITION FASTIN FASTON TAB HOUSING (PA)	 TE Part # 928309-7 7P FF FLACHST GEH	 TE Part # 293034-1 7 POSITION FASTIN FASTON TAB HOUSING (PA)



TE Part # 1-927742-6
6 POS. FASTIN-FASTON* TAB HSG
RAST5

TE Part # 5-1241969-8
FASTIN FASTON HOUSING 8P

TE Part # 1241857-5
5 POS FASTIN/ON HOUSING PANEL
MOUNT

TE Part # 293267-1
7 POS. FASTIN-FASTON+ TAB
HOUSING RAST 5

Also in the Series | RAST 5 IDC Connectors

Connector Contacts(12)

Crimp Terminal Housings(39)

Insertion & Extraction Tools(1)

PCB Headers & Receptacles(417)

Power Contacts(3)

Rectangular Power Connectors(481)

Standard Edge Connectors(31)

Wire-to-Board Headers & Receptacles
(417)

Customers Also Bought

TE Part #336075-3
250 FASTON,REC.,20-16 AWG,PTBR

TE Part #336076-3
250 FASTON,E-SPRING REC.,17-14
AWG,PTBR

TE Part #182923-1
CPC PLUG ASSY SIZE 23-37

TE Part #42474-4
250 FASTON TAB 18-14 AWG TPBR

Documents

Product Drawings
8 POS. FASTIN-FASTON CONN. TAB HSG, RAST
English

CAD Files
3D PDF
3D



Customer View Model

[ENG_CVM_CVM_284986-1_B.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_284986-1_B.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_284986-1_B.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[FASTIN_FASTON_Product_Line](#)

English

[RAST Connector System Catalog](#)

English

Product Specifications

[Product Specification](#)

English