

 
Article-No.	Length	EAN-Code	Head	Handles	mm
	mm	4003773			0
99 00	200	014393	polished	black atrimentized	220
	220	013273			320
	250	013280			400
	280	014096			460
	300	014409			480
99 01	200	021452	polished	plastic-coated	235
	220	021469			350
	250	021483			415
	280	021490			485
	300	014416			510
99 00	220	027812	polished	black atrimentized	325
	K 12				
99 11	200	021520	polished	plastic-coated	255

- for steel binding wire – quick, reliable and low cost
- to twist and cut binding wire in one operation
- precision and long life make these the most widely purchased tool in the world
- Material: special tool steel, oil-hardened
- No. 99 00 220 K 12 with 12 mm head width, especially suitable for trimming and shaping mosaic tiles
- Model 99 11 200: Easier cutting as a result of higher leverage (end cutting character), head width 24 mm, cutting capacity: soft wire up to max. 3.0 mm in diameter

99 Concretors' Nippers

(Tower Pincers / Steel Fixers Nippers)


DIN ISO 9242



99 00 280



99 01 220

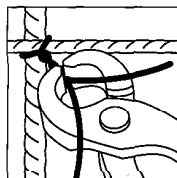

99 01 220



99 11 200