


## Rapid 12 mm Professional Glue Multi-purpose GEN-T

These 12 mm, multi-purpose glue sticks deliver quality bonding thanks to high resin levels and are perfect for a wide range of professional applications. Available in large, practical packs ideal for Pro or Industrial users.

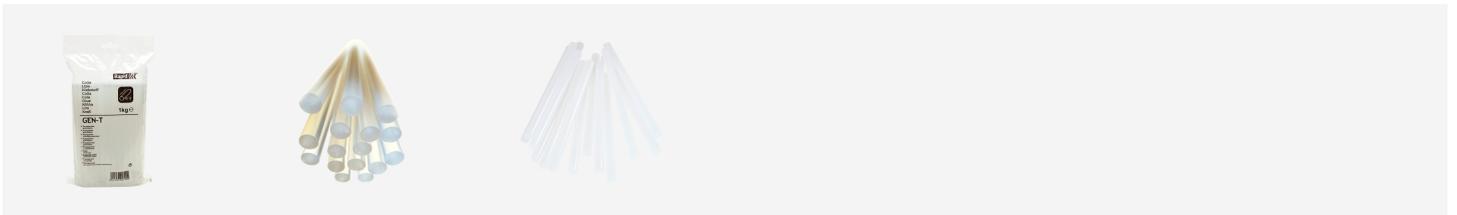

### Attributes

- Ø12 x 190 mm
- High resin levels
- Application temperature: 160-200 °C
- Softening point: 81-84 °C
- Open time: 60 sec
- Set time: 30 sec
- 1 kg, packed in plastic bag
- For EG212, EG250, CG270, EG280, BGX300, EG310, EG320, EG330, EG340, EG360, EG380



### Specifications

Number	40302799
Colour	-----
Material	EVA and resin
Dimensions (W x H x D)	155 x 55 x 200 mm
Glue stick diameter	12 mm
Package content	1 kg
Suitable for	Multi-purpose use
Miscellaneous	GEN-T Glue D12x190mm 1Kg Bag AT12 - P-09-001 - 190
Weight	1030 g
Packing unit	10
Pallet quantity	420
Minimum order quantity	1
EAN code	3221633027999