

PRODUCT SPECIFICATION

**Carl
Kammerling**
International


Brand	C.K
Product Range	Blue Steel Screwdriver Bits & Sets
Catalogue number	4560, 4510, 4511, 4512, 4513
Date	26/01/2015

Range Description

Features

- Manufactured from specially formulated V* steel alloy for extreme toughness
- Features torsion control technology to withstand the stresses of high torque applications
- Blue steel impact bits provide a vastly extended working life
- Colour coded for convenience



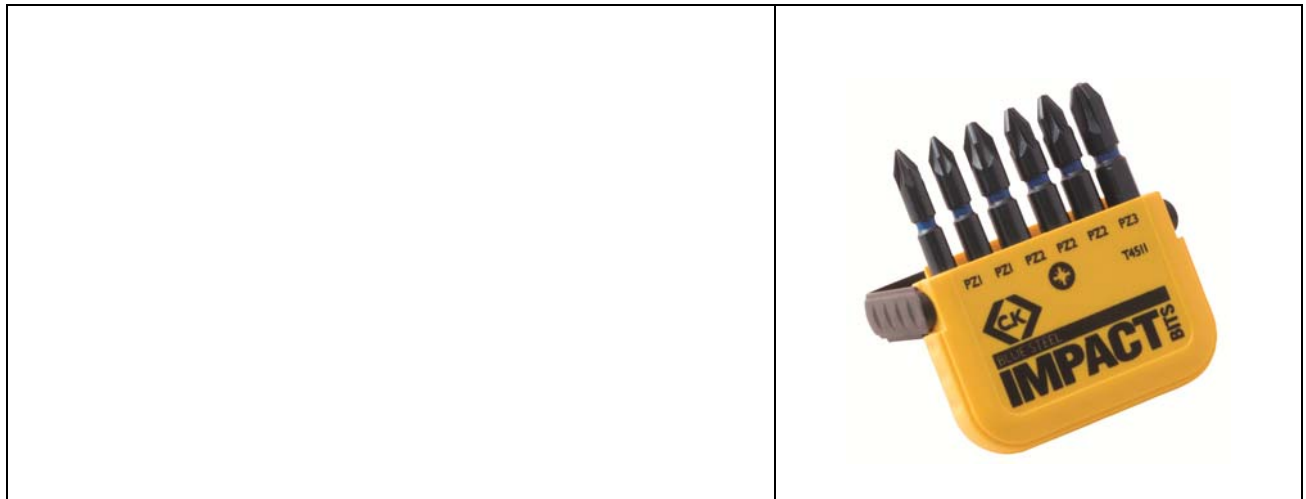

Item Number	Item Description	EAN No	Commodity code	Shelf box Qty
T4560 PZ1	Blue Steel Screwdriver Bit PZ1 x 25mm-Loose	-	82079030	10
T4560 PZ2	Blue Steel Screwdriver Bit PZ2 x 25mm-Loose	-	82079030	10
T4560 PZ3	Blue Steel Screwdriver Bit PZ3 x 25mm-Loose	-	82079030	10
T4560 PZ1D	Blue Steel Screwdriver Bit PZ1 x 25mm-Carded triple pack	5013969996685	82079030	20
T4560 PZ2D	Blue Steel Screwdriver Bit PZ2 x 25mm-Carded triple pack	5013969996678	82079030	20
T4560 PZ3D	Blue Steel Screwdriver Bit PZ3 x 25mm-Carded triple pack	5013969996692	82079030	20
T4560 PZ1L	Blue Steel Screwdriver Bit PZ1 x 50mm-Loose	-	82079030	10
T4560 PZ2L	Blue Steel Screwdriver Bit PZ2 x 50mm-Loose	-	82079030	10
T4560 PZ1LD	Blue Steel Screwdriver Bit PZ1 x 50mm-Carded triple pack	5013969996715	82079030	20
T4560 PZ2LD	Blue Steel Screwdriver Bit PZ1 x 50mm-Carded triple pack	5013969996722	82079030	20
T4560 PZ2D15	Blue Steel Screwdriver Bit PZ2 x 25mm-Box of 15	5013969996753	82079030	12
T4560 PZ2LD10	Blue Steel Screwdriver Bit PZ2 x 50mm-Box of 10	5013969996760	82079030	12
T4560 PH1	Blue Steel Screwdriver Bit PH1 x 25mm-Loose	-	82079030	10
T4560 PH2	Blue Steel Screwdriver Bit PH2 x 25mm-Loose	-	82079030	10
T4560 PH3	Blue Steel Screwdriver Bit PH3 x 25mm-Loose	-	82079030	10
T4560 PH2L	Blue Steel Screwdriver Bit PH2 x 50mm-Loose	-	82079030	10
T4560 PH2LD	Blue Steel Screwdriver Bit PH2 x 50mm-Carded triple pack	5013969996746	82079030	12
T4560 SL45	Blue Steel Screwdriver Bit Slotted 0.6x4.5mm, 25mm Loose	-	82079030	10
T4560 SL55	Blue Steel Screwdriver Bit Slotted 1.0x5.5mm, 25mm Loose	-	82079030	10

T4560 SL65	Blue Steel Screwdriver Bit Slotted 1.2x5mm, 25mm Loose	-	82079030	10
T4560 TX05	Blue Steel Screwdriver Bit TX05 x 25mm – Loose	-	82079030	10
T4560 TX06	Blue Steel Screwdriver Bit TX06 x 25mm – Loose	-	82079030	10
T4560 TX07	Blue Steel Screwdriver Bit TX07 x 25mm – Loose	-	82079030	10
T4560 TX08	Blue Steel Screwdriver Bit TX08 x 25mm – Loose	-	82079030	10
T4560 TX09	Blue Steel Screwdriver Bit TX09 x 25mm – Loose	-	82079030	10
T4560 TX10	Blue Steel Screwdriver Bit TX10 x 25mm – Loose	-	82079030	10
T4560 TX15	Blue Steel Screwdriver Bit TX15 x 25mm – Loose	-	82079030	10
T4560 TX20	Blue Steel Screwdriver Bit TX20 x 25mm – Loose	-	82079030	10
T4560 TX25	Blue Steel Screwdriver Bit TX25 x 25mm – Loose	-	82079030	10
T4560 TX27	Blue Steel Screwdriver Bit TX27 x 25mm – Loose	-	82079030	10
T4560 TX30	Blue Steel Screwdriver Bit TX30 x 25mm – Loose	-	82079030	10
T4560 TX40	Blue Steel Screwdriver Bit TX05 x 25mm – Loose	-	82079030	10
T4560 TXTP10	Blue Steel Screwdriver Bit TXTP10 x 25mm – Loose	-	82079030	10
T4560 TXTP15	Blue Steel Screwdriver Bit TXTP15 x 25mm – Loose	-	82079030	10
T4560 TXTP20	Blue Steel Screwdriver Bit TXTP20 x 25mm – Loose	-	82079030	10
T4560 TXTP25	Blue Steel Screwdriver Bit TXTP25 x 25mm – Loose	-	82079030	10
T4560 TXTP30	Blue Steel Screwdriver Bit TXTP30 x 25mm – Loose	-	82079030	10
T4560 HEX25	Blue Steel Screwdriver Bit Hex 2.5mm x 25mm – Loose	-	82079030	10
T4560 HEX30	Blue Steel Screwdriver Bit Hex 3.0mm x 25mm – Loose	-	82079030	10
T4560 HEX40	Blue Steel Screwdriver Bit Hex 4.0mm x 25mm – Loose	-	82079030	10
T4560 HEX50	Blue Steel Screwdriver Bit Hex 5.0mm x 25mm – Loose	-	82079030	10
T4560 HEX60	Blue Steel Screwdriver Bit Hex 6.0mm x 25mm – Loose	-	82079030	10
T4560 ROB1	Blue Steel Screwdriver Bit Robertson 1 x 25mm – Loose	-	82079030	10
T4560 ROB2	Blue Steel Screwdriver Bit Robertson 2 x 25mm – Loose	-	82079030	10
T4560 ROB3	Blue Steel Screwdriver Bit Robertson 3 x 25mm – Loose	-	82079030	10
T4510	10 piece mixed bits set 25mm	5013969996630	82079030	20
T4511	6 piece mixed PZD set 50mm	5013969996647	82079030	20
T4512	6 piece mixed PH set 50mm	5013969996654	82079030	20
T4513	6 Piece mixed Torx set 50mm	5013969996661	82079030	20

Technical product information	
Standards compliance	All 25mm Bits have DIN 3126-C6,3. ISO 1173 drive All 50mm single ended bits have DIN 3126-E6,3. ISO 1173 drive
User health and safety information	
RoHS/WEEE compliance	This product range does not fall within the scope of RoHS or WEEE regulations
Material safety data	None applicable
Warranty	C.K screwdriver bits are guaranteed for life against imperfect materials or workmanship Normal wear and tear or damage caused through inappropriate use is not covered
Country of origin	Taiwan

Dimensional details

Item	Product only (Not on packaging)				Product on primary packaging			
	Width mm	Depth mm	Height mm	Net weight g	Width mm	Depth mm	Height mm	Gross weight g
T4560 PZ1	6	6	25	6	-	-	-	-
T4560 PZ2	6	6	25	6	-	-	-	-
T4560 PZ3	6	6	25	6	-	-	-	-
T4560 PZ1D	6	6	25	6	55	130	10	21
T4560 PZ2D	6	6	25	6	55	130	10	24
T4560 PZ3D	6	6	25	6	55	130	10	26
T4560 PZ1L	6	6	50	10	-	-	-	-
T4560 PZ2L	6	6	50	10	-	-	-	-
T4560 PZ1LD	6	6	50	10	55	155	11	37
T4560 PZ2LD	6	6	50	10	55	155	11	37
T4560 PZ3LD	6	6	50	10	55	155	11	37
T4560 PZ2D15	45	25	90	92	45	25	90	92
T4560 PZ2LD10	45	25	90	124	45	25	90	124
T4560 PH1	6	6	25	6	-	-	-	-
T4560 PH2	6	6	25	6	-	-	-	-
T4560 PH3	6	6	25	6	-	-	-	-
T4560 PH2L	6	6	50	10	-	-	-	-
T4560 PH2LD	6	6	50	10	55	155	11	37

T4560 SL45	6	6	25	6	-	-	-	-
T4560 SL55	6	6	25	6	-	-	-	-
T4560 SL65	6	6	25	6	-	-	-	-
T4560 TX05	6	6	25	6	-	-	-	-
T4560 TX06	6	6	25	6	-	-	-	-
T4560 TX07	6	6	25	6	-	-	-	-
T4560 TX08	6	6	25	6	-	-	-	-
T4560 TX09	6	6	25	6	-	-	-	-
T4560 TX10	6	6	25	6	-	-	-	-
T4560 TX15	6	6	25	6	-	-	-	-
T4560 TX20	6	6	25	6	-	-	-	-
T4560 TX25	6	6	25	6	-	-	-	-
T4560 TX27	6	6	25	6	-	-	-	-
T4560 TX30	6	6	25	6	-	-	-	-
T4560 TX40	6	6	25	6	-	-	-	-
T4560 TXTP10	6	6	25	6	-	-	-	-
T4560 TXTP15	6	6	25	6	-	-	-	-
T4560 TXTP20	6	6	25	6	-	-	-	-
T4560 TXTP25	6	6	25	6	-	-	-	-
T4560 TXTP30	6	6	25	6	-	-	-	-
T4560 HEX25	6	6	25	6	-	-	-	-
T4560 HEX30	6	6	25	6	-	-	-	-
T4560 HEX40	6	6	25	6	-	-	-	-
T4560 HEX50	6	6	25	6	-	-	-	-
T4560 HEX60	6	6	25	6	-	-	-	-
T4560 ROB1	6	6	25	6	-	-	-	-
T4560 ROB2	6	6	25	6	-	-	-	-
T4560 ROB3	6	6	25	6	-	-	-	-
T4510	-	-	-	-	140	135	20	97
T4511	-	-	-	-	120	120	10	88
T4512	-	-	-	-	120	120	10	88
T4513	-	-	-	-	120	120	10	88

Shelf (Inner) box (secondary packaging)				
Item	Width mm	Depth mm	Height mm	Net weight g

Item	Width mm	Depth mm	Height mm	Net weight g
-------------	-----------------	-----------------	------------------	---------------------

T4560 PZ1	60	115	7	61
T4560 PZ2	60	115	7	61
T4560 PZ3	60	115	7	61
T4560 PZ1D	55	155	110	450
T4560 PZ2D	55	155	110	510
T4560 PZ3D	55	155	110	550
T4560 PZ1L	60	115	10	101
T4560 PZ2L	60	115	10	101
T4560 PZ1LD	55	155	110	770
T4560 PZ2LD	55	155	110	770
T4560 PZ3LD	55	155	110	770
T4560 PZ2D15	100	160	100	1134
T4560 PZ2LD10	100	160	100	1228
T4560 PH1	60	115	7	61
T4560 PH2	60	115	7	61
T4560 PH3	60	115	7	61
T4560 PH2L	60	115	7	61
T4560 PH2LD	60	115	7	101
T4560 SL45	60	115	7	61
T4560 SL55	60	115	7	61
T4560 SL65	60	115	7	61
T4560 TX05	60	115	7	61
T4560 TX06	60	115	7	61
T4560 TX07	60	115	7	61
T4560 TX08	60	115	7	61
T4560 TX09	60	115	7	61
T4560 TX10	60	115	7	61
T4560 TX15	60	115	7	61
T4560 TX20	60	115	7	61
T4560 TX25	60	115	7	61
T4560 TX27	60	115	7	61
T4560 TX30	60	115	7	61
T4560 TX40	60	115	7	61
T4560 TXTP10	60	115	7	61
T4560 TXTP15	60	115	7	61

T4560 TXTP20	60	115	7	61
T4560 TXTP25	60	115	7	61
T4560 TXTP30	60	115	7	61
T4560 HEX25	60	115	7	61
T4560 HEX30	60	115	7	61
T4560 HEX40	60	115	7	61
T4560 HEX50	60	115	7	61
T4560 HEX60	60	115	7	61
T4560 ROB1	60	115	7	61
T4560 ROB2	60	115	7	61
T4560 ROB3	60	115	7	61
T4510	140	160	150	1419
T4511	110	160	150	1131
T4512	110	160	150	1131
T4513	110	160	150	1131

Packaging waste details

Item	Primary Packaging				Secondary packaging (shelf box + any other material not used in display)			
	Plastic g	Use	Card g	Use	Plastic g	Use	Card g	Use
T4560 PZ1	-	-	-	-	1	Bag	-	-
T4560 PZ2	-	-	-	-	1	Bag	-	-
T4560 PZ3	-	-	-	-	1	Bag	-	-
T4560 PZ1D	1	Blister	5	Card	-	-	30	Box
T4560 PZ2D	1	Blister	5	Card	-	-	30	Box
T4560 PZ3D	1	Blister	5	Card	-	-	30	Box
T4560 PZ1L	-	-	-	-	1	Bag	-	-
T4560 PZ2L	-	-	-	-	1	Bag	-	-
T4560 PZ1LD	2	Blister	5	Card	-	-	30	Box
T4560 PZ2LD	2	Blister	5	Card	-	-	30	Box
T4560 PZ3LD	2	Blister	5	Card	-	-	30	Box
T4560 PZ2D15	-	-	-	-	--	-	30	Box

T4560 PZ2LD10	-	-	-	-	-	-	30	Box
T4560 PH1	-	-	-	-	1	Bag	-	-
T4560 PH2	-	-	-	-	1	Bag	-	-
T4560 PH3	-	-	-	-	1	Bag	-	-
T4560 PH2L	-	-	-	-	1	Bag	-	-
T4560 PH2LD					1	Bag	-	-
T4560 SL45	-	-	-	-	1	Bag	-	-
T4560 SL55	-	-	-	-	1	Bag	-	-
T4560 SL65	-	-	-	-	1	Bag	-	-
T4560 TX05	-	-	-	-	1	Bag	-	-
T4560 TX06	-	-	-	-	1	Bag	-	-
T4560 TX07	-	-	-	-	1	Bag	-	-
T4560 TX08	-	-	-	-	1	Bag	-	-
T4560 TX09	-	-	-	-	1	Bag	-	-
T4560 TX10	-	-	-	-	1	Bag	-	-
T4560 TX15	-	-	-	-	1	Bag	-	-
T4560 TX20	-	-	-	-	1	Bag	-	-
T4560 TX25	-	-	-	-	1	Bag	-	-
T4560 TX27	-	-	-	-	1	Bag	-	-
T4560 TX30	-	-	-	-	1	Bag	-	-
T4560 TX40	-	-	-	-	1	Bag	-	-
T4560 TXTP10	-	-	-	-	1	Bag	-	-
T4560 TXTP15	-	-	-	-	1	Bag	-	-
T4560 TXTP20	-	-	-	-	1	Bag	-	-
T4560 TXTP25	-	-	-	-	1	Bag	-	-
T4560 TXTP30	-	-	-	-	1	Bag	-	-
T4560 HEX25	-	-	-	-	1	Bag	-	-
T4560 HEX30	-	-	-	-	1	Bag	-	-
T4560 HEX40	-	-	-	-	1	Bag	-	-

T4560 HEX50	-	-	-	-	1	Bag	-	-
T4560 HEX60	-	-	-	-	1	Bag	-	-
T4560 ROB1	-	-	-	-	1	Bag	-	-
T4560 ROB2	-	-	-	-	1	Bag	-	-
T4560 ROB3	-	-	-	-	1	Bag	-	-
T4510	5	Blister	10	Card	-	-	75	Box
T4511	4	Blister	10	Card	-	-	75	Box
T4512	4	Blister	10	Card	-	-	75	Box
T4513	4	Blister	10	Card	-	-	75	Box