

# Screw Clamp 15 mm DIN-Rail Terminals

- Feed Through
- Fuse
- Disconnect
- Ground
- Thermocouple

Weidmüller's 15 mm DIN-rail terminals are similar in design and function to the SAK-Series, but their smaller dimensions make them particularly useful in miniaturized equipment.

Like the SAK, the miniature blocks are available in both Polyamide 6.6 and Melamine.

## AKZ 1.5

 


## AKZ 2.5




## AKZ 4

for test adapter



## AKZ 4/10

for test adapter

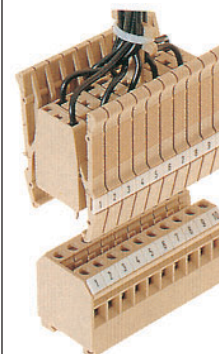

Available Options	Version	AKZ 1.5	AKZ 2.5	AKZ 4	AKZ 4/10
	KrG			0294320000	
	PA	0340460000	0697160000 (with spigot)	0294360000	0359560000 without marking
	Blue PA	0340480000	0697180000 (with spigot)	0294380000	
	PA	0358060000 (10 pole w/o mark.)	0175960000 (without spigot)		
	PA	0358160000 (10 pole w/mark.)	0385860000 AKZ 2.5 with AP	1538260000 for test adapter	1489360000 w/mark./for test ad.
	Test adapter ATA1				1633240000 10 pole
<b>Dimensions</b>					
Width / Length / Height mm (in.)	with TS 15	5/25/25 (.197/.98/.98)	5/25.5/27 (.197/1/1.06)	6/27/30 (.24/1/1.18)	60/27/30 (2.36/1/1.18)
Insulation stripping length	mm (in.)	7 (.28)	7 (.28)	9 (.35)	9 (.35)
<b>Technical Data</b>					
Rated voltage / rated current / wire size	UL	150 V / 15 A / #22...14 AWG	300 V / 10 A / #26...12 AWG	300 V / 27 A / #22...12 AWG	300 V / 27 A / #22...12 AWG
	CSA	300 V / 10 A / #24...16 AWG	300 V / 10 A / #26...10 AWG	300 V / 10 A / #24...12 AWG	300 V / 10 A / #24...12 AWG
	VDE	250 VAC / 18 A / 1.5 mm <sup>2</sup>	250 VAC / 26 A / 2.5 mm <sup>2</sup>	380 VAC / 34 A / 4 mm <sup>2</sup>	380 VAC / 34 A / 4 mm <sup>2</sup>
Torque	Nm (lb. in.)	0.4 (4.5)	0.4 (4.5)	0.5 (8.0)	0.5 (8.0)
Clamping screw	M	2.5	2.5	3	3
<b>End Plate (thickness mm)</b>					
	KrG			AP (1.5) 0294420000	
	Blue KrG				
	PA	AP (1.5) 0340560000	AP (2.5) 0697360000	AP (1.5) 0294460000	AP (1.5) 0294460000
	Blue PA		AP (2.5) 0697380000	AP (1.5) 0294480000	
<b>Partition (thickness mm)</b>					
	Blue KrG				
	Blue KrS				
	PA		TW (1.5) 0318560000	TW (0.5) 0348260000	TW (0.5) 0348260000
	Blue PA		TW (1.5) 0318580000		
<b>Small Partition</b>					
	PA			TSch 4 0363360000	TSch 4 0363360000
<b>Jumpers</b>					
		Q2 0368200000	Q2 0368200000	Q2 0336400000	Q2 0336400000
		Q3 0368300000	Q3 0368300000	Q3 0336500000	Q3 0336500000
		Q4 0368400000	Q4 0368400000	Q4 0336600000	Q4 0336600000
		Q5 0660300000	Q5 0660300000		
		Q10 0368500000	Q10 0368500000	Q10 0368600000	Q10 0368600000
<b>Jumpering Link</b>					
				VL 2 0446700000	VL 2 0446700000
				VH 10 0446600000	VH 10 0446600000
				BS M 2.5x14 0266800000	BS M 2.5x14 0266800000
<b>Cover / Cover Profile for Shock Protection*</b>					
			Dekafix can be snapped	AD 4 0303400000	AD 4 0303400000
			over cross-connection slot	BSK M 2.5x18 0303300000	BSK M 2.5x18 0303300000
				ADP 4** 1378160000	ADP 4** 1378160000
<b>Test Plugs / Sockets</b>					
	Plug / test socket usable without QL	StB 8.5 0215700000	StB 8.5 0215700000	StB 8.5 0215700000	StB 8.5 0215700000
	PS				
	StB				
	For #18 AWG wire	PS 2.3 0180400000	PS 2.3 0180400000	PS 2.3 0180400000	PS 2.3 0180400000
<b>Marking Tags</b>					
	Print	DEK 5/5 0473460001	DEK 5/5 0473460001	DEK 5/5 0473460001	DEK 5/5 0473460001
	Consecutive horizontal	DEK 5/5 0473560001	DEK 5/5 0473560001	DEK 5/5 0473560001	DEK 5/5 0473560001
	Consecutive vertical				

See Accessories section for mounting rails, end brackets, test taps, additional marking material and accessories.