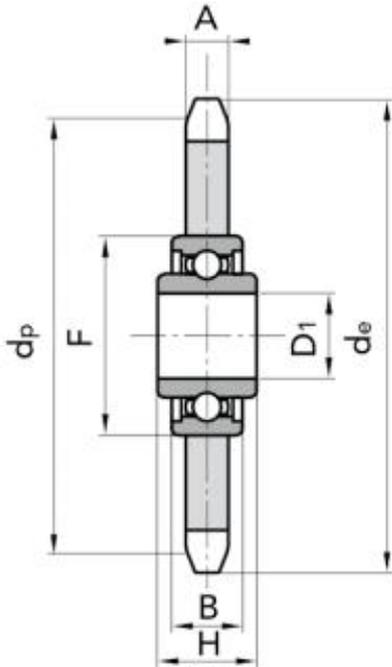
 


30015014

With economic bearing - Idler sprocket

2D Technical Drawing

Dynamic 3D View

Technical Specifications

Number of teeth (T)	14
Pitch (P) mm	5/8" x 3/8"
de (DE) mm	78
dp (DP) mm	71.34
Part number (CODE)	30015014
A (A) mm	9.1
D1 (D1) mm	16
F (F) mm	40
B (B) mm	12
H (H) mm	18.3
Weight (WEIGHT) kg	0.23
Material (MAT)	STEEL C45