


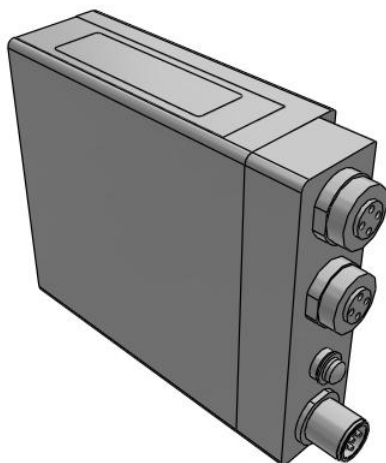

EX260, Integrated Type (For Output) Serial Transmission System EX260-FPS1

Datasheet


General series information

- Centralised & compact serial transmission system for output
- Compatible protocols: PROFI-safe, Ethernet POWERLINK, PROFINET, EtherNet/IP™, EtherCAT®, PROFIBUS DP, DeviceNet™, CC-Link, IO-Link, CANopen, Modbus, AS-Interface
- Up to 32 solenoids, up to 24 stations
- Applicable valve series: new SY, VQC, S0700, SV
- Up to IP67 enclosure compliant.

Standard specifications

Protocol	PS (PROFI-safe)
Output Polarity/Communication Connector	1 [32 Outputs, -COM (PNP), M12 Connector]
Maximum ambient temperature	50 °C
Minimum ambient temperature	-10 °C
General power supply	24 VDC
Approvals	CE marking, UL (CSA) compatible
Weight	0.175 Kg

Dimensions

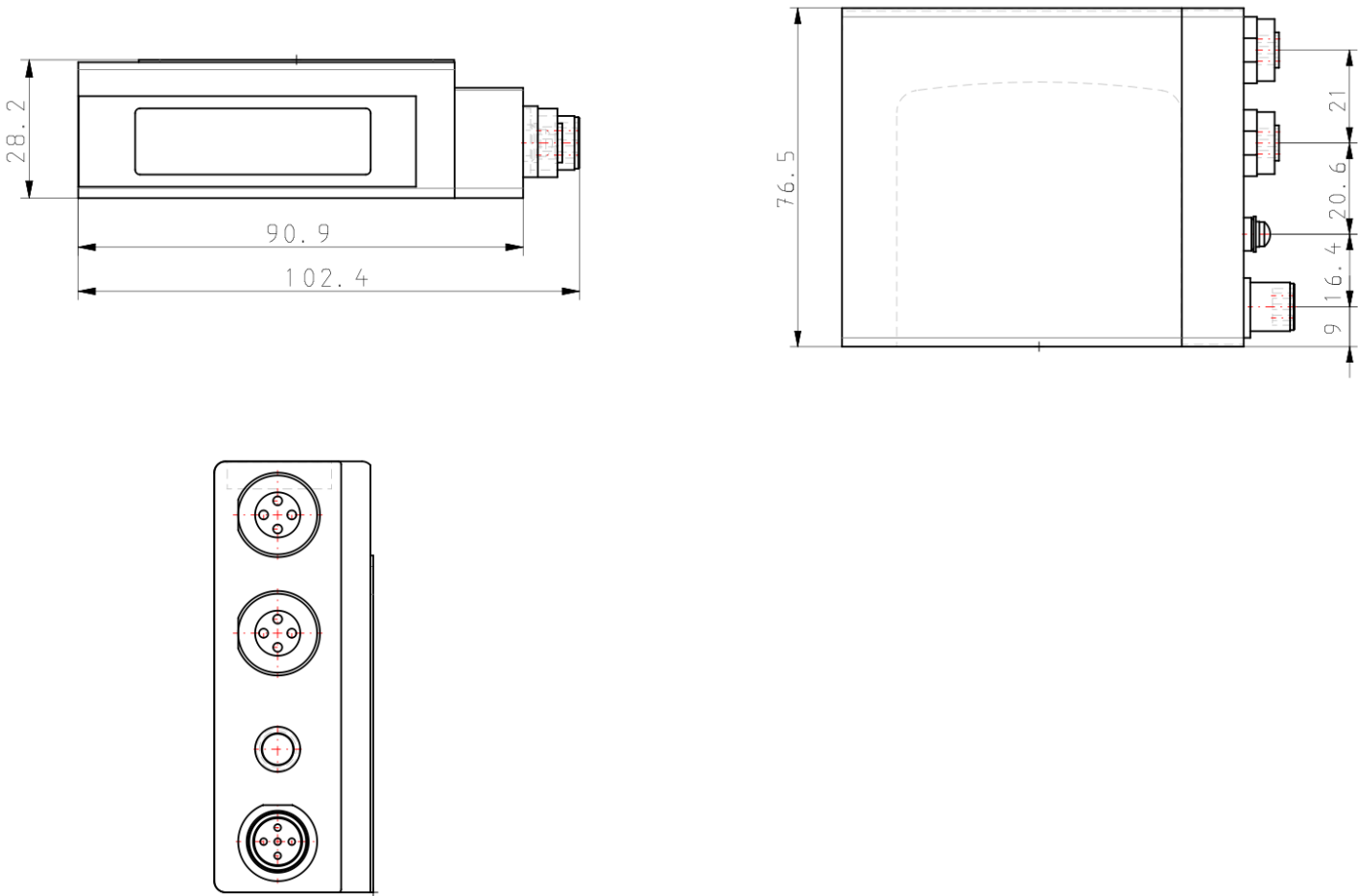

Specifications are subject to change without prior notice and any obligation on the part of the manufacturer.

Additional information

Catalogue	EX260-D_EU.pdf
Declaration of conformity	newDoC_EX260_EN-A.pdf newDoC_EX260_PROFIsafe_EN-C.pdf newDoC_EX260_PROFIBUS_DeviceNet_EtherCAT_PROFINET_EtherNetIP_EtherNet-POWERLINK_CC-Link_EN-A.pdf
Installation manuals	IM_EX260_EtherNet_POWERLINK_EN.pdf IM_EX260_DeviceNet_EN.pdf IM_EX260_CC-Link_EN.pdf IM_EX260_PROFINET_EN.pdf IM_EX260_IO-Link_EN.pdf IM_EX260_EtherNetIP_EN.pdf IM_EX260_PROFIsafe_EN.pdf IM_EX260_EtherCAT_EN.pdf
Operation manuals	OM_EX260_CC-Link_EN-I.pdf OM_EX260_IP_Address_Setting_Tool_EX9-ZSW-IPC1_EN-A.pdf EX260_EtherNetIP_Quickguide_en.pdf Quick_guide_EX260_PROFIBUS_EN.pdf Quick_guide_EX260_EtherNet_POWERLINK_EN.pdf OM_EX260_EtherNet_POWERLINK_EN-A.pdf OM_EX260_EtherNetIP_EN-F.pdf OM_EX260_IO-Link_EN-A.pdf Quick_guide_EX260_EtherCAT_EN.pdf Quick_guide_EX260_DeviceNet_EN.pdf