

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2157112105](#)
Status: **Active**
Overview: [Off-the-Shelf Pre-Crimped Leads](#)
Description: Pre-Crimped Lead Clik-Mate Male-to-Pigtail, Tin (Sn) Plating, 450.00mm Length, 28 AWG, Red

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	215711
Application	Signal, Wire-to-Board
Assembly Configuration	Pre-crimped Lead Only
Connector to Connector	CLIK-Mate-to-CLIK-Mate
Overview	Off-the-Shelf Pre-Crimped Leads
Product Name	CLIK-Mate
UPC	193264605255


Physical

Cable Length	450.00mm
Circuits (Loaded)	1
Color - Resin	Red
Gender	Male-Pigtail
Material - Metal	Copper Alloy
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.627/g
Packaging Type	Bag
Plating min - Mating	0.406µm
Plating min - Termination	0.406µm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.78-1.28mm
Wire Size AWG	28
Wire/Cable Type	UL 10002

Electrical

Current - Maximum per Contact	2.0A
Voltage - Maximum	100V AC (RMS)/DC

Material Info

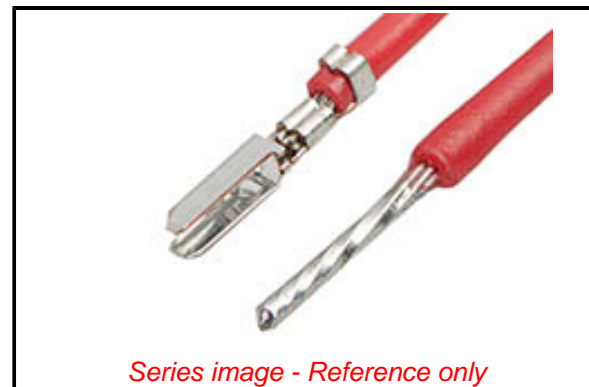

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[215711 Series](#)

Use With

[CLIK-Mate Housing 502578](#) , [503149](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION