

Gravity-feed spray gun for industrial spray painting



Technical characteristics


Construction: Body : Aluminium
Needle : Stainless steel

Applications: Automotive and industrial sectors

Highlight: Three types of adjustment (width of stream, paint flow rate and air flow rate)

BSPP male thread: G 1/4

Blue anodised aluminium body
0,6-litre polyamide cup
Working pressure: 3,5 to 5 bar
Air consumption: 250 to 320 l/min
Weight: 600 g
G 1/4 M connection
M16 x 1,5P cup connection thread

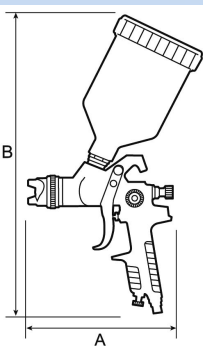

A (mm)	B (mm)	Nozzle Ø (mm)	Parts Numbers
160	325	1.4	CAR G04
160	325	1.7	CAR G041
160	325	2	CAR G042