

o Flat Cable Connectors SEK

o har-mik®

o D-Sub

o InduCom

Applications



Product details

09 18 540 5803

IDC female connector

Termination	Flat cable insulation displacement
Connector size	40 contacts
IDC strain relief clamp	Without strain relief
Cover	With an open end cover
Centre polarization	With central polarisation
Performance level	AU-0.76•m [30• Inch]
RoHS compliant	Yes

Available Downloads


Title	Format	
Data sheet	PDF	download
CAD data 2D	DXF	download

Further links

3D-Library



Inquiry

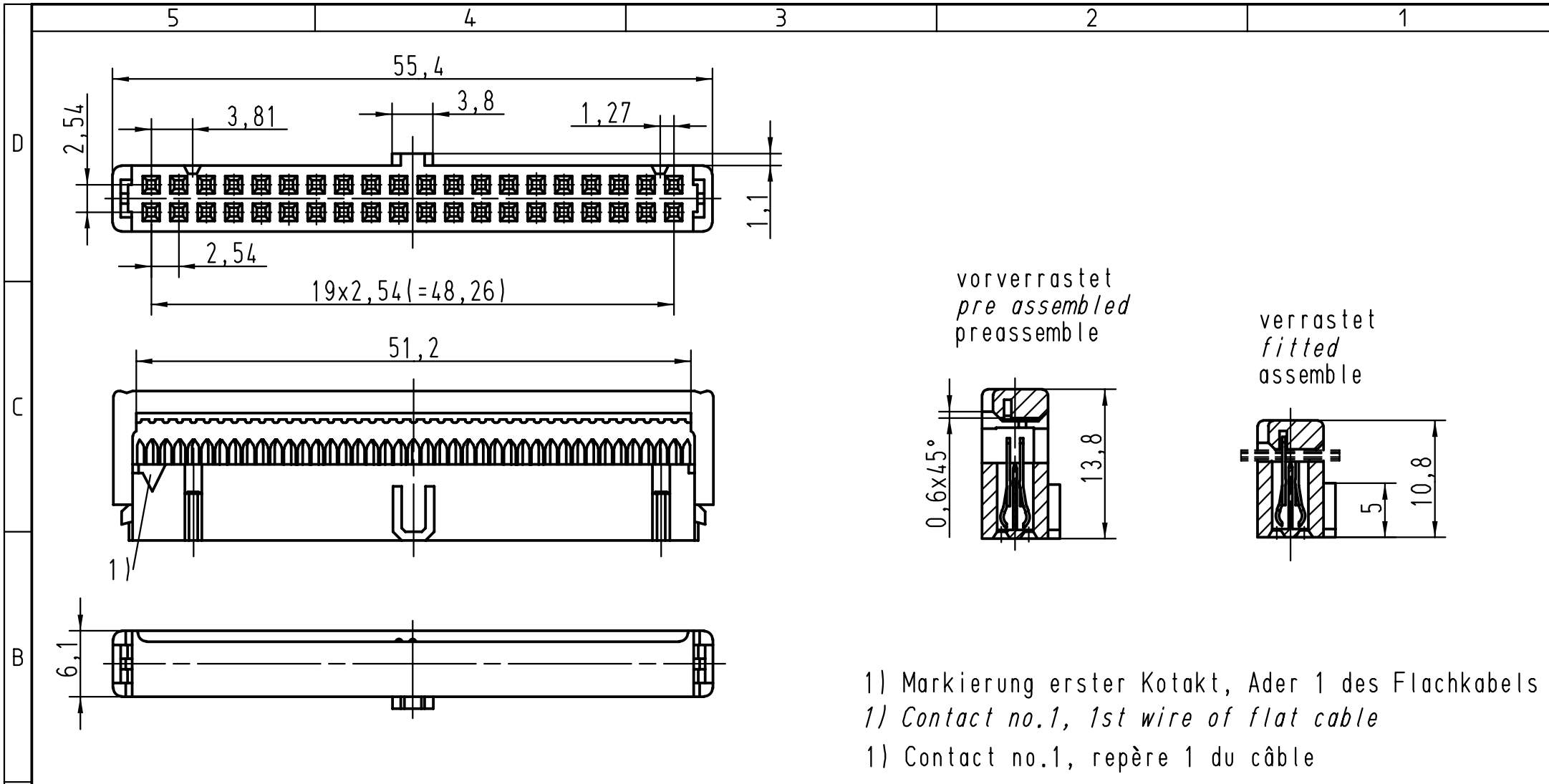

1) Markierung erster Kontakt, Ader 1 des Flachkabels
 1) Contact no.1, 1st wire of flat cable
 1) Contact no.1, repère 1 du câble

		All Dimensions in mm Original Size DIN A 4			Techn. Character.			Nicht tolerierte Masse/ Free size tolerances			
A	09185405803	0,76 μm Au			Detail.	Dat.	Name	Massstab/Scale 2:1	SEK 18 Female connector 40 poles with central polarisation cover without cable stop		
	09185406803	2			Insp.	01-FEB-00	JMV				
	09185407803	3			Stand.						
Bestell-Nr. Part-No. Reference		Anforderungsstufe performance level Niveau de qualite		26570	01-FEB-00	JB	HARTING EURL F-95972 Paris		TB 0918540X803		Blatt/ page 1/1
				Mod.	Dat.	Name			Sub.		