

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0151350203**
Status: **Active**
Overview: CLIK-Mate™ Wire-to-Board Connectors
Description: CLIK-Mate™-to-CLIK-Mate™ Off-the-Shelf (OTS) Cable Assembly, Single Row, 300.00mm Length, 2 Circuits, Beige

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|-----------------------------|---|
| Product Family | Cable Assemblies |
| Series | 15135 |
| Assembly Configuration | Dual Ended Connectors |
| Connector to Connector | CLIK-Mate™-to-CLIK-Mate™ |
| Overview | CLIK-Mate™ Wire-to-Board Connectors |
| Product Literature Order No | 987651-6143 |
| Product Name | CLIK-Mate™ OTS |
| UPC | 191128154543 |

Physical

| | |
|--------------------------------|----------------------|
| Cable Length | 300.00mm |
| Circuits (Loaded) | 2 |
| Color - Resin | Beige |
| Gender | Male-Male |
| Lock to Mating Part | Yes |
| Material - Metal | Copper Alloy |
| Material - Plating Mating | Tin |
| Material - Plating Termination | Tin |
| Material - Resin | PBT |
| Net Weight | 2.363/g |
| Packaging Type | Bag |
| Pitch - Mating Interface | 1.50mm |
| Plating min - Mating | 0.406µm |
| Plating min - Termination | 0.406µm |
| Single Ended | No |
| Termination Interface: Style | Crimp or Compression |
| Wire Insulation Diameter | 1.10mm |
| Wire Size AWG | 24 |
| Wire/Cable Type | UL 1061 |


Electrical

| | |
|-------------------------------|------------------|
| Current - Maximum per Contact | 1.5A |
| Voltage - Maximum | 100V AC (RMS)/DC |

Material Info

Reference - Drawing Numbers

| | |
|---------------|----------------|
| Sales Drawing | 2012341673-000 |
|---------------|----------------|

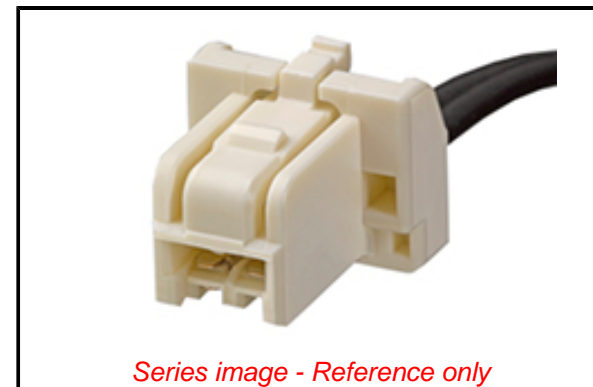

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

| | |
|-----------------|---------------|
| China ROHS | Green Image |
| ELV | Not Relevant |
| RoHS Phthalates | Not Contained |

Search Parts in this Series

[15135](#) Series

Mates With

[503395](#) Bottom-Entry Receptacle . [503175](#) Right Angle, Through Hole Receptacle .
[502585](#) Right Angle, Surface Mount Receptacle
 [503159](#) Vertical, Through Hole Receptacle
 [502584](#) , [505405](#) Vertical, Surface Mount Receptacle