


Professional Contractor LED Tape

5M282/CW/NW/WW

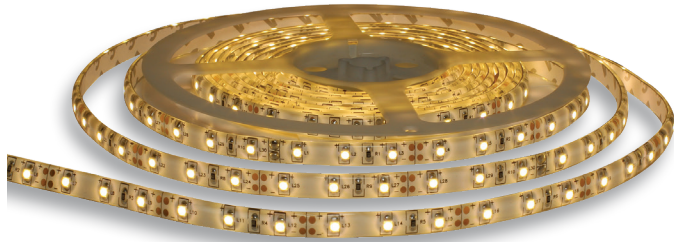

Single colour flexible tape available in cool, neutral and warm white. Comes complete with 3M ultra adhesive backing for easy installation.



SPECIFICATION FOR IP65


LED STRIP	5M28265CW	5M28265NW	5M28265WW
Colour	Cool White	Neutral White	Warm White
CCT	6000K	4000K	3000K
Lumens:	800lm	800lm	800lm
Operating Voltage:	24VDC	24VDC	24VDC
Power per meter:	9.6W/m	9.6W/m	9.6W/m
Number of LEDs:	60LEDs/m	60LEDs/m	60LEDs/m
LED Type:	2835	2835	2835
IP Rating	IP65	IP65	IP65
Cutting Point:	100mm	100mm	100mm
Lifetime:	30k hours	30k hours	30k hours

SPECIFICATION FOR IP20

LED STRIP	5M28220CW	5M28220NW	5M28220WW
Colour	Cool White	Neutral White	Warm White
CCT	6000K	4000K	3000K
Lumens:	800lm	800lm	800lm
Operating Voltage:	24VDC	24VDC	24VDC
Power per meter:	9.6W/m	9.6W/m	9.6W/m
Number of LEDs:	60LEDs/m	60LEDs/m	60LEDs/m
LED Type:	2835	2835	2835
IP Rating	IP20	IP20	IP20
Cutting Point:	100mm	100mm	100mm
Lifetime:	30k hours	30k hours	30k hours



Mechanical

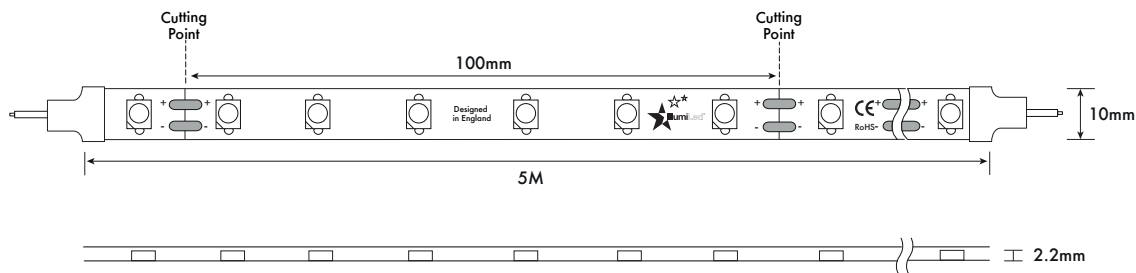

IllumiLed
Orion House
Calleva Park
Aldermaston
Berkshire
RG7 8SN

Contact:
Tel: 0118 9408740
sales@illumiled.co.uk
www.illumiled.co.uk