


113A.12C 113A.C - Chromed adjustable wrenches

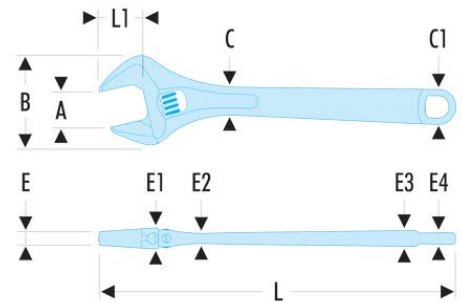

- Good access to the button = easy setting.
- Non-protruding moving jaw at maximum capacity.
- Pre-adjustment of jaw opening thanks to millimetric gradation.
- Right-hand button rotation.
- Range from 4" to 24".
- Presentation: chromed body and polished head faces.

A [mm]: 34

B [mm]: 80,0

C x C1 [mm]: 25,0 x 31,0

C1 [mm]: 31

E [mm]: 10,0

E maxi [mm]: 10

E1 [mm]: 18,0

E2 [mm]: 10,2

E3 [mm]: 13,0

E4 [mm]: 10,0

L [mm]: 306

L1 [mm]: 34

[g]: 700