


Alphabetical Picture Part Number
SEARCH SEARCH SEARCH

Go To Step Search™ Screen

34070 -- 1 of 1 products

Terminals and Splices
Splices - Closed Barrel

General **INFO**
Sales **INFO**
Customer Drawings **SPECIFICATIONS**

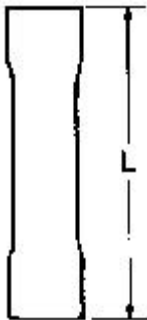

Line art represents typical product only.

<i>Searchable Features:</i>	
Product Type	Splice
Splice Type	Butt
Butt Splice Type	Standard
Body Style	PLASTI-GRIP
Insulation	Yes
Insulation Support	Insulation Support
Insulation Diameter	.140 [3.56] Max. in. [mm]
Wire Range	22-16 [0.26-1.65 ²] AWG [mm]
Wire Range (CMA)	509-3,260
Material	Copper
Finish	Tin
Packaging Method	Loose Piece
<i>Other Properties:</i>	
Dim. L	1.076 [27.33] Max. in. [mm]
Insulation Sleeve Material	Vinyl
Color	Red
CERTI-CRIMP Hand Tool	47386-4, 525690-0 (Great Britain Tool)
CERTI-LOK Hand Tool Frame Assembly	169400
CERTI-LOK Die Assembly	169404
Comment	22-16 splices are 22-18 range in accordance with MIL-T-7928.