


## Datasheet

### Point Spring - loaded test terminal

RS Stock number [521-611](#)

Dimensions: (mm)

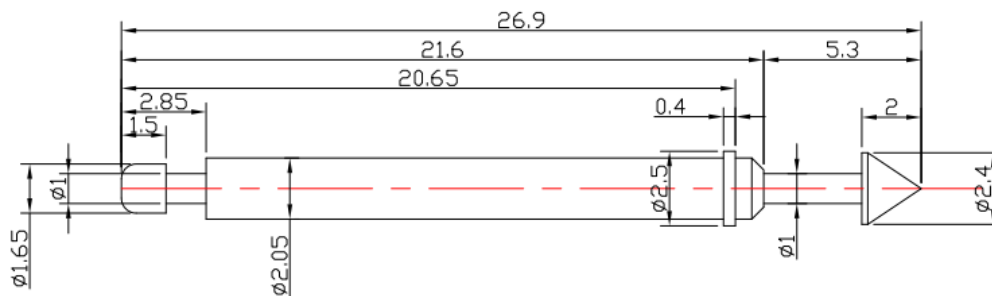

## Specifications

- Plunger: Heat-Treated Beryllium Copper with Rhodium Plated over Nickel
- Spring: Stainless Steel
- Barrel: Phosphor Bronze with Gold Plated

(min center) : 2.54mm [0.10]

(full stroke): 21#            23#

4.2            3.0mm

[0.1654]    [0.1181]

- Full Stroke Spring Force: + 20% 150g [5.29oz]
- 2/3 Stroke Spring Force: + 20% 115g [4.06oz]
- Current Rating: 3A
- Contact Resistance: 30m Ω
- Recommended Hole Size: Acrylic - 1.70mm[0.0669]  
                                          Bakelite – 1.75mm[ 0.0689]  
                                          Fiber Reinforced Plastic – 1.75mm [0.0689]