


## Datasheet

### M6 Die x 1mm Pitch , 25mm od

RS Stock number 668-0722

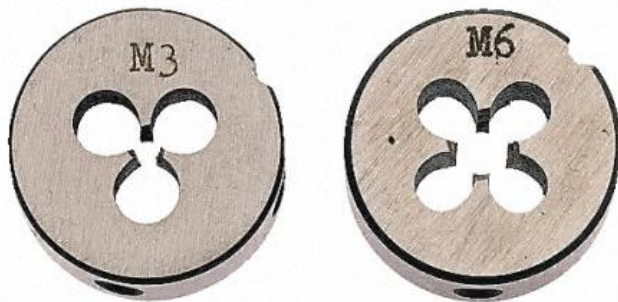

#### HSS Circular Dies, BS1127, Left hand thread, with split

RS STOCK NUMBER		Size(mm)	Outside Diameter	Thickness (mm)
6680744		M3X0.5	13/16"(20.63mm)	6.35
6680753		M4x0.7	13/16"(20.63mm)	6.35
6680756		M5x0.8	13/16"(20.63mm)	6.35
6680750		M6x1.0	13/16"(20.63mm)	6.35
6680769		M8x1.25	1 5/16"(33.33mm)	11.11
6680762		M10x1.5	1 5/16"(33.33mm)	11.11
6680766		M12x1.75	1 5/16"(33.33mm)	11.11

#### HSS Circular Dies, DIN223, without split

RS STOCK NUMBER		Size(mm)	Outside Diameter(mm)	Thickness (mm)
6680716		M3X0.5	25	9
6680725		M4x0.7	25	9
6680728		M5x0.8	25	9
6680722		M6x1.0	25	9
6680731		M8x1.25	25	9
6680734		M10x1.5	25	9
6680738		M12x1.75	25	9
6680740		3/8-24UNF	25.4	9
6680747		1/4-28UNF	25.4	9
6680775		M3-M12	25	9