


Part Number: 1904X00X

| Type | Size | Rating | Description |
|------|------|--------|-------------------------------|
| LED | M8 | - | LED Prominent Panel Indicator |

Dimensions in mm (Not to scale)

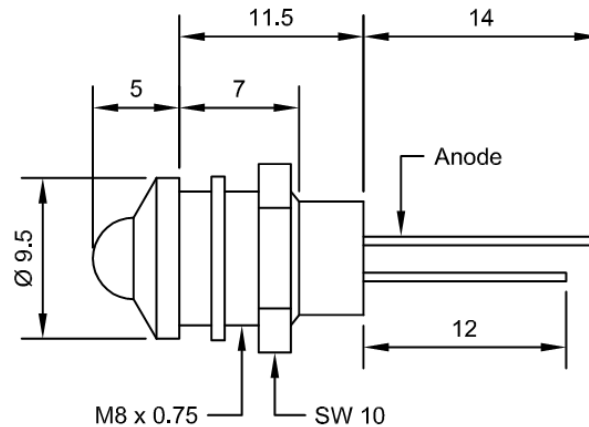

| Part # | Colour | Typ. V _f | Typ. Luminous Intensity (mcd @ 10mA) |
|----------|--------|---------------------|--------------------------------------|
| 1904X003 | Red | 2.0 | 25 |
| 1904X001 | Green | 2.2 | 20 |
| 1904X002 | Yellow | 2.1 | 20 |
| 1904X007 | Blue | 3.8 | 45 |
| 1904X008 | Orange | 2.0 | 30 |
| 1904X00W | White | 3.2 | 1000 |

Bezel types - X=0 satin chrome / X=1 black chrome / X=2 matt chrome

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 Stated luminous intensity is for DC operation
- 3 Storage temperature -25 °C to +80°C
- 4 Application temperature -20 °C to +60°C
- 5 Due to component tolerances, colour temperature variations may be observed
- 6 Ingress protection rating: IP40
- 7 The plastic (polycarbonate) has limited chemical resistance
- 8 RoHS & REACH SVHC compliant