


REXEL LAMINATING MACHINES

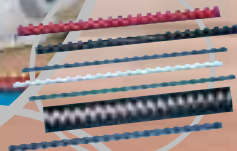

Rexel Business Machines

*Your No. 1 partner
for document presentation,
protection and security*

ACCO, the world-leading office products company,
has the most powerful brand portfolio in the business –
including Rexel Business Machines.

All around the world, Rexel, Nobo, Kensington,
Twinlock, Swingline and Wilson Jones help to put people
in control of their workspace.

No.1 for Experience and New Ideas

For more than 50 years Rexel have been creating and building products wholly
responsive to their users' needs. An unusual blend of engineering skills,
innovation and classically simple design has produced many firsts in binding,
laminating and shredding. Today, it produces products that take both
form and function to new heights.

No1 for Style and Innovation

For many people, Rexel products mean style and innovation. As brand leaders
they dominate a crowded market through the quality of their design and the unique
features they offer to the user.

We are always looking for new ways of thinking, always moving away from the
commonplace in search of new ideas.

The new Rexel binder range brings together a host of new ideas and features:
all are about improved performance, about working more simply, about making
life easier for the user.

No1 for Reliability

As we see it, to be the best we must also be the most reliable. Skilled
engineering, new ideas and superb design all combine with one purpose – to do
the job better. And to be there when needed. That's reliability. That's what you
get from products that perform.



LAMINATING

Protection and Preservation

Lamination will extend the life of any document, especially if it is frequently handled. Lamination protects a document from dirt and damage and gives it a durable, wipe-clean surface which is totally sealed and waterproof.

Enhancement

The laminating pouch bonds itself into the surface of the document, so that it looks brighter and cleaner. Text appears crisper while colours are enhanced or subdued, depending whether a gloss or matt finish is chosen.

Security

Any document is tamper-proof once it has been sealed within the laminating pouch. It is impossible to amend or change a laminated document nor can it be removed from the laminated seal.

Rexel Laminating Pouches

Rexel Laminating Pouches are compatible with Rexel branded and most other laminating machines. Only the best quality materials are used in their manufacture and all sizes have rounded corners to ensure safe handling and provide a more attractive finish.

Carriers are included with all Rexel Laminators and also with packs of Rexel Laminating Pouches. The document to be laminated is simply placed inside the laminating pouch and then the carrier to provide added protection during the lamination process.

'Carrier-free' machines can be used without a carrier, which makes laminating large quantities of documents less time-consuming. However, a carrier protects valued documents from coming into contact with any glue or dust inside the laminator and its use is recommended for an exceptionally pristine result.



Personal Laminators - LV Series

The LV Series of personal laminators offers outstanding value for money, producing excellent results at low cost.

LV340

The LV340 offers a versatile, low cost solution to all your laminating needs, from Badge up to A3 size.

- 340mm entry accepts pouch sizes from Badge to A3
- Takes pouches up to 2x125 (250) micron thickness, with perfect results every time. Also handles 2x180 (360) micron pouches up to A7 size
- Fast warm up time with 'ready' light when correct temperature is reached
- Fast speed (33cm per minute)
- Variable temperature control, including settings for self seal pouches and Rexel Photopouches
- Comes complete with a starter pack of pouches and an A4 carrier

Code: 2100163

LV250

The LV250 offers a low cost solution to laminating documents up to A4 size.

- 250mm entry accepts pouch sizes from Badge to A4
- Takes pouches up to 2x125 (250) micron thickness, with perfect results every time. Also handles 2x180 (360) micron pouches up to A7 size
- Fast warm up time with 'ready' light when correct temperature is reached
- Fast speed (33cm per minute)
- Variable temperature control, including a cold setting for self-seal pouches and a photo setting for use with Rexel Photopouches
- Comes complete with a starter pack of assorted pouches and a carrier

Code: 2100161



Easy adjustment



Easy to produce excellent results



Fast operation




LV250

LV340

Model	LV250	LV340
Rollers	2	2
Carrier/Carrier Free	Carrier	Carrier
Maximum Pouch Size	A4	A3
Maximum Pouch Thickness A4/A3	2x125 (250) micron A4	2x125 (250) micron A3
Maximum Pouch Thickness A7	2x180 (360) micron A7	2x180 (360) micron A7
Temperature Control	Variable	Variable
Speed Control	Fixed	Fixed
Dimensions (mm)	98x445x217	100x533x235
Weight (Kg)	2.9	3.5
Ref. No	2100161	2100163

2 Roller Laminating Process

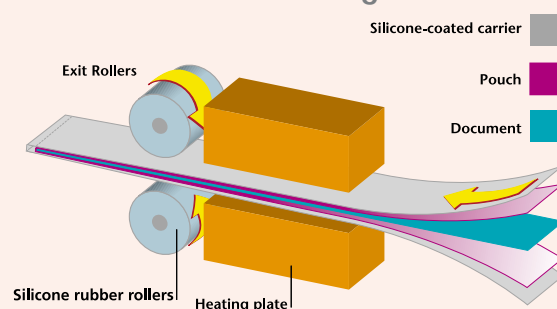

Office Laminators - LP Series

The new LP Office Laminators are easy to use, attractively styled four-roller machines that give superb results without the need for a pouch carrier. Offering excellent value for money, they're the ideal machines for home or office use.

LP35

The LP35 protects, preserves and enhances all types of documents up to A3 size. It can be used with or without a carrier.

- 340mm entry accepts pouch sizes from ID up to A3
- Handles pouches up to 2x180 (360) micron thickness
- Fast warm-up time with 'ready' light when correct temperature is reached
- Fixed speed – an exceptionally fast 48cm per minute!
- Variable temperature control including a cold setting for self-seal pouches, a photo setting for use with Rexel Photopouches and standard pouch settings
- Carrier or carrier-free operation
- Comes complete with a generous starter pack of assorted pouches and an A4 carrier

Code: 2100511

LP25

The LP25 protects, preserves and enhances all types of document up to A4 size. It can be used with or without a carrier.

- 250mm entry accepts pouch sizes from ID up to A4
- Handles pouches up to 2x180 (360) micron thickness
- Fast warm-up time with 'ready' light when correct temperature is reached
- Fixed speed – an exceptionally fast 48cm per minute!
- Variable temperature control including a cold setting for self-seal pouches, a photo setting for use with Rexel Photopouches and standard pouch settings
- Carrier or carrier-free operation
- Comes complete with a generous starter pack of assorted pouches and a carrier

Code: 2100509



Easy adjustment



LP35

LP25

LP10

The neat, compact LP10 is simple to use and produces strong, durable badges, entry passes, membership cards, luggage tags and much more.

- 120mm entry accepts pouch sizes from ID to A7
- Handles pouches up to 2x180 (360) micron thickness
- Fast warm up time with 'ready' light when correct temperature is reached
- Fixed speed and temperature control
- Comes complete with a starter pack of pouches


Code: 41635



LP10

Model	LP10	LP25	LP35
Rollers	4	4	4
Carrier/Carrier Free	Carrier Free	Carrier Optional	Carrier Optional
Maximum Pouch size	A7	A4	A3
Maximum Pouch thickness	2x180 (360) micron	2x180 (360) micron	2x180 (360) micron
Temperature Control	Fixed	Variable	Variable
Speed Control	Fixed	Fixed	Fixed
Dimensions (mm)	70 x 200 x 164	98 x 445 x 217	100 x 533 x 235
Weight (kg)	2	4.4	5.4
Ref. No	41635	2100509	2100511

4 Roller Laminating Process

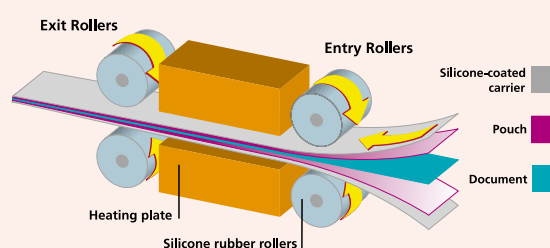

Office Laminators - LM Series

This range of stylish laminators was developed following two years of research into what users really want from an office laminator. The result is an outstanding combination of innovative design and advanced features which provide the perfect laminating solution within the corporate environment.

LM35

The LM35 is the ideal machine for medium volume use and is packed with features to ensure professional results.

- Extra wide entry accepts all pouch sizes from ID up to A3
- Handles pouches up to 2x180 (360) micron thickness
- LCD display shows when power is on, the temperature setting and when to laminate
- Fast speed of 50cm per minute
- Variable temperature control with six pre-set programmes
- Integral worktable allows easy document assembly and pouch storage
- Comes complete with a starter pack of pouches and an A4 carrier

Code: 41628GB

LM45

The high performance LM45 features a fully adjustable operating system which provides inexperienced users with professional results at the touch of a button. At the same time, the more experienced operator can fine tune the speed and temperature settings according to their particular needs, achieving the best possible results every time.

- Extra-wide entry accepts all pouch sizes from ID up to A3
- Handles pouches up to 2x180 (360) micron thickness
- Comprehensive LCD display shows when power is on, temperature and speed settings and when to laminate
- Variable speed control, between 20cm and 70cm per minute
- Variable temperature control, with six pre-set programmes or option to select exact temperature required
- Reverse button prevents and clears document jams
- Autostart and autostop functions reduce office noise and wear and tear on the machine
- Carrier or carrier-free operation
- Useful pouch storage inside integral worktable
- Comes complete with a starter pack of pouches and an A4 pouch carrier

Code: 41629GB



LM35




LM45



Adjustable speed control

Model	LM35	LM45
Rollers	4	4
Carrier/Carrier Free	Carrier	Carrier Optional
Maximum Pouch size	A3	A3
Maximum Pouch thickness	2x180 (360) micron	2x180 (360) micron
Temperature Control	Variable	Variable
Speed Control	Fixed	Variable
Worktable & storage	Yes	Yes
LCD Display	Yes	Yes
Auto Start/Stop & Reverse		Yes
Energy Saving Standby		Yes
Dimensions (mm)	101 x 483 x 325	101 x 483 x 325
Weight (kg)	4.4	5.0
Ref. No.	41628GB	41629GB

4 Roller Laminating Process

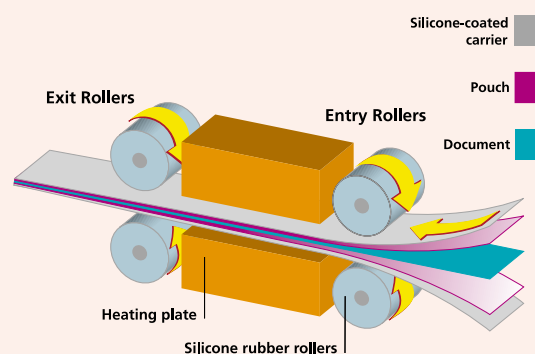

Rexel Laminating Pouches

Pouch Finishes

Standard Gloss Finish produces enhanced, rich colours for a bright, clear, high shine appearance.

The Matt Finish results in more subtle colours and a non-reflective surface which can be written on.



A3 GLOSS



A3 MATT



A3 Gloss Finish

Size	Finish	Thickness	Pack of 25	Pack of 100
A3	Gloss	2 x 75micron	41617	41616
A3	Gloss	2 x 100micron	N/A	46311
A3	Gloss	2 x 125micron	41619	41618
A3	Gloss	2 x 180micron	41620	N/A

A4 Gloss Finish

Size	Finish	Thickness	Pack of 25	Pack of 100
A4	Gloss	2 x 75micron	41622	41621
A4	Gloss	2 x 100micron	N/A	46310
A4	Gloss	2 x 125micron	41624	41623
A4	Gloss	2 x 180micron	41625	N/A

Matt Finish A4/A3

Size	Finish	Thickness	Pack of 25	Pack of 100
A4 non-reflective	Matt	2 x 75micron	41662	44626
A4 non-reflective	Matt	2 x 125micron	41663	N/A
A3 non-reflective	Matt	2 x 75micron	41661	41660

A5 Gloss Finish

Size	Finish	Thickness	Pack of 25	Pack of 100
A5	Gloss	2 x 75micron	41650	41653
A5	Gloss	2 x 125micron	41652	41651

A6/A7 Gloss Finish

Size	Finish	Thickness	Pack of 50	Pack of 100
A6	Gloss	2 x 75micron		41668
A7	Gloss	2 x 125micron	41669	

Credit Card/Badge

Size	Finish	Thickness	Pack of 50	Pack of 100
Credit Card (54x86mm)	Gloss	2 x 125micron	41670	
Credit Card (54x86mm)	Gloss	2 x 180micron	41608	
IBM card (59x83mm)	Gloss	2 x 180micron	41609	
Key Card (63x98mm)	Gloss	2 x 180micron	41610	
Badge (67x98mm)	Gloss	2 x 180micron	41611	



Rexel Laminating Pouches

Pre-punched pouches

These gloss pouches have a border pre-punched for use with all standard-sized ring binders.



Pre-punched A4

Size	Finish	Thickness	Pack of 25	Pack of 100
A4 prepunched	Gloss	2 x 75micron	41665	41664

Self-adhesive pouches

These gloss pouches have a self-adhesive backing to give a secure fixing for use as laminated signage.



Self-adhesive A4

Size	Finish	Thickness	Pack of 25	Pack of 100
A4 self-adhesive back	Gloss		41667	41666

Rexel Photopouches

These specially constructed pouches produce excellent, 'bubble free' results on photographs and other hard to laminate material.



Photopouches

Size	Finish	Thickness	Pack of 50
2.5"x3.5"	Gloss	2 x 100 (200) micron	2100155
6"x4"	Gloss	2 x 100 (200) micron	2100156
7"x5"	Gloss	2 x 100 (200) micron	2100157
10"x8"	Gloss	2 x 100 (200) micron	2100158
A4	Gloss	2 x 100 (200) micron	2100159

Rexel Pouch Selection Pack

A selection of 80 of the most popular laminating pouches for home and office use in one, convenient pack.



Pouch Selection Pack

Contents	2100230
50 x A4 gloss, 10 x A4 matt and 10 x A4 gloss prepunched pouches (2 x 75 (150) micron) plus 5 x credit card size and 5 x bag tag size (2 x 125 (250) micron) and 5 plastic loops	

Rexel Laminating Kits & Accessories

Size	Finish	Thickness	Pack of 25	Pack of 50
Bag Tag Kit	Gloss	2 x 125micron	41674	
Pre punched luggage tag pouches (64x108mm) and plastic loops				
Luggage Tag Kit	Gloss	2 x 180micron	41675	41612
Pre punched luggage tag pouches (64x108mm) and Black leather straps				
Badge Kit	Gloss	2 x 125micron	41676	
Pre punched badge pouches (67x98mm) and lapel clips				
Neckchains				41613
Neckchains fit through a hole or slot in a laminate and are used to wear a badge round the neck				
Lapel Clips				41614
Lapel clips attach through a slot in the laminate and are used to attach badges to clothing				

Size	
Hand Slot Punch	41615 each
Punch to make slots for neckchains and lapel clips	
A3 Card Carriers	41677 Pack of 5
A4 Card Carriers	41678 Pack of 5



Badge Kit



Luggage Tag Kit



ACCO UK & International

Gatehouse Road
Aylesbury
Bucks. HP19 3DT
Great Britain
☎ 01296 397444 ☎ 01296 489539

ACCO Polska

Falenty Nowe
ul. Rozy 11
05-090 Raszyn
Polska
☎ 022 720 5300 ☎ 022 720 3458

ACCO Benelux

Peppelkade 64
3992 AK Houten
Nederland
☎ 030 634 6060 ☎ 030 634 6070



ACCO EUROPE
www.accoeurope.com

ACCO France

Rue Ampère BP33
91430 Igny Zai
France
☎ 01 69 85 8900 ☎ 01 69 85 8992

ACCO Italia

10036 Settimo Torinese (TO)
Via Regio Parco 108 / bis
Italy
☎ 011 896 1111 ☎ 011 896 1234

ACCO Deutschland

Hetzel GmbH & Co. KG
Schorndorfer Str. 69
D-73635 Rudersberg-Steinberg
Germany
☎ 0049 0 7183 3003-54
☎ 0049 0 7183 3003-52
Email: hotline@accodeutschland.de

ACCO Hungária KFT

Óscai út 4
1239 Budapest
Hungária
☎ 00 36 1 2 83 16 45
☎ 00 36 1 2 83 09 28

ACCO Ireland

Clonsaugh Industrial Estate
Clonsaugh
Dublin 17
Republic of Ireland
☎ 00 353 1 8164300
☎ 00 353 1 8164302

ACCO North America
300 Tower Parkway
Lincolnshire
IL 60069-3640
U.S.A.
☎ 847 541 9500 ☎ 847 419 4139

ACCO Česká Republika

Hetzel GmbH & Co. KG
Kapitána Sochora 2400
39003 Tábor
Česká Republika
☎ 0 04 20 38 18 94 00
☎ 0 04 20 3 61 23 11 05

ACCO Nordic

Kanalvagen 10c, 9tr
194 61 Upplands Vasby
Sweden
☎ 08 59 00 4244 ☎ 08 59 00 4110

ACCO Canada

Acco Canada Inc.
501 McNicoll Avenue
Ontario
☎ 416 499 1000 ☎ 416 499 0757