

# KDT-ST 17 - Filler plug



3062061

<https://www.phoenixcontact.com/gb/products/3062061>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Filler plug, material: PA, length: 20 mm, diameter: 17 mm



## Commercial data

|                                      |                     |
|--------------------------------------|---------------------|
| Item number                          | 3062061             |
| Packing unit                         | 25 pc               |
| Minimum order quantity               | 25 pc               |
| Sales key                            | AF7CZX              |
| Product key                          | AF7CZX              |
| Catalog page                         | Page 682 (C-2-2019) |
| GTIN                                 | 4046356309011       |
| Weight per piece (including packing) | 4.472 g             |
| Weight per piece (excluding packing) | 4.333 g             |
| Customs tariff number                | 39174000            |
| Country of origin                    | DE                  |

# KDT-ST 17 - Filler plug



3062061

<https://www.phoenixcontact.com/gb/products/3062061>

## Technical data

 
### Notes

|         |                                                         |
|---------|---------------------------------------------------------|
| General | The filler plugs are used to seal unused cable sleeves. |
|---------|---------------------------------------------------------|

### Product properties

|              |               |
|--------------|---------------|
| Product type | Sealing plugs |
|--------------|---------------|

### Dimensions

|                     |                                                                                    |
|---------------------|------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Length              | 20 mm                                                                              |
| Diameter            | 17 mm                                                                              |

### Material specifications

|          |                  |
|----------|------------------|
| Color    | black (RAL 9005) |
| Material | PA               |

### Environmental and real-life conditions

|                                 |                                          |
|---------------------------------|------------------------------------------|
| Ambient conditions              |                                          |
| Degree of protection            | IP54 (Observe the assembly instructions) |
| Ambient temperature (operation) | -20 °C ... 80 °C                         |

### Mounting

|               |                                                                                                                    |
|---------------|--------------------------------------------------------------------------------------------------------------------|
| Assembly note | IP54: for vertical sealing frame mounting/for horizontal sealing frame mounting (downward cable outlet direction). |
|---------------|--------------------------------------------------------------------------------------------------------------------|

# KDT-ST 17 - Filler plug


3062061

<https://www.phoenixcontact.com/gb/products/3062061>




## Drawings

Dimensional drawing

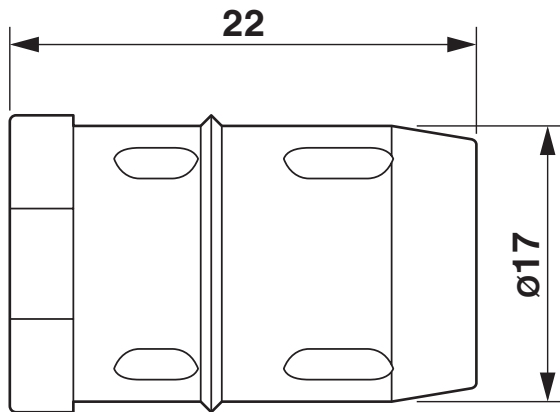

Dimensional drawing

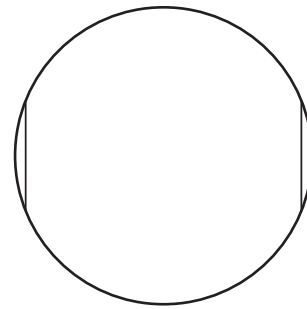

# KDT-ST 17 - Filler plug

3062061

<https://www.phoenixcontact.com/gb/products/3062061>



## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 23111190 |
|-------------|----------|

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000032 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39121300 |
|-------------|----------|

# KDT-ST 17 - Filler plug

3062061

<https://www.phoenixcontact.com/gb/products/3062061>



## Environmental product compliance

### EU RoHS

|                                         |                    |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

### China RoHS

|                                        |                                          |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|                                        | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd  
Halesfield 13, Telford  
Shropshire, TF7 4PG  
01952 681700  
[info@phoenixcontact.co.uk](mailto:info@phoenixcontact.co.uk)