

Features

- Strong and durable stainless steel construction
- 120-degree opening angle
- Removable pin which allows quick and easy removal of the door, giving improved access for maintenance
- Easy mounting via either metric bolts or rivets

RS PRO Hinges

RS Stock No.: 0335155



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description


Stainless steel hinge, pin and circlip. 120 degree opening angle. A removeable pin allows the door to be separated from the enclosure, giving improved access. The pin is secured with a circlip. Designed for use in industrial enclosures and cabinets.

General Specifications

Length	90mm
Material	Stainless steel 304
Opening angle	120 degrees
Colour	Grey
Application	Enclosures, HVAC, machinery, equipment, construction industry
Radial load (N)	500
Axial load (N)	980

Mechanical Specifications

A	90
B	25
C	25
D	5.2
E	6.5
F	9.5
G	23
H	27.5

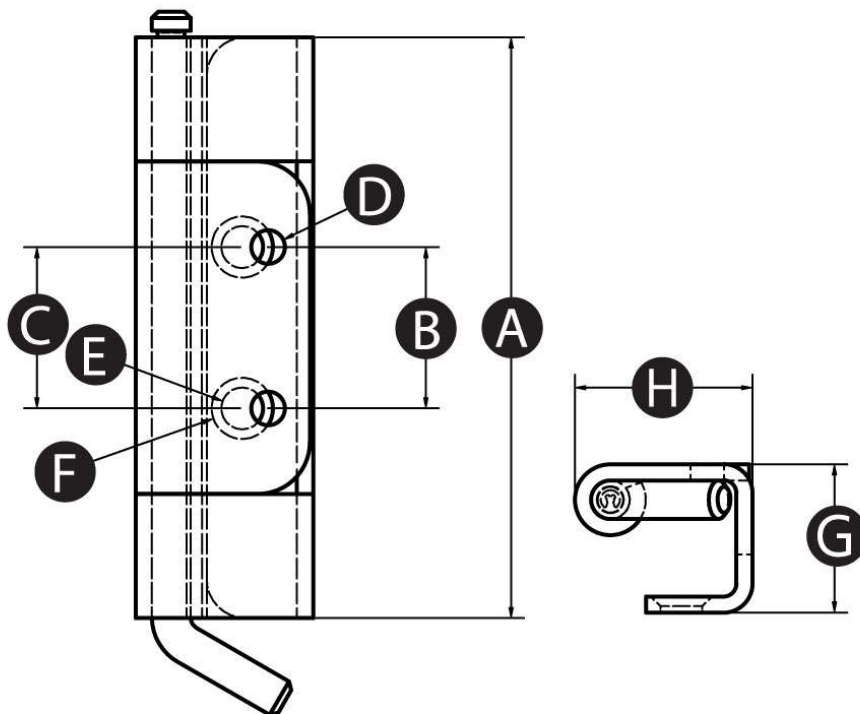

Similar Products

Stock No.	Brand	Product Name	Length	Height	Opening Angle
0335155	RS PRO	Stainless Steel Concealed Hinge	90mm	27.5mm	120 degrees
0335158	RS PRO	Stainless Steel Concealed Hinge	90mm	33.5mm	120 degrees
0335156	RS PRO	Stainless Steel Concealed Hinge	90mm	24mm	120 degrees