 



## 600X600 LED PANEL WITH HIGH VISUAL COMFORT

LD3PAN3853U9

38,0 W - 3400lm - 4000K

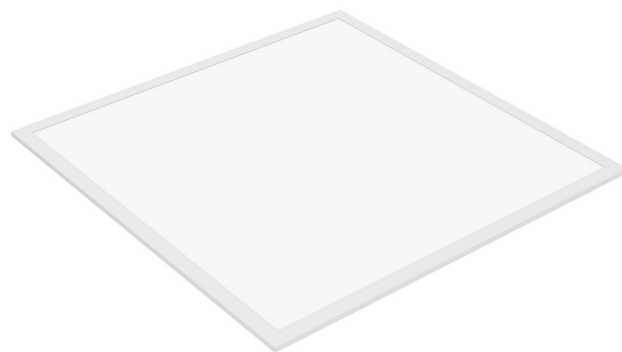

DIMENSIONS	A	B	C
1	10	595	595












Driver compreso  
nella confezione /  
Driver included

### GENERAL INFORMATIONS

Code	LD3PAN3853U9
Ean	8031453022969
Family	600X600 LED PANEL WITH HIGH VISUAL COMFORT
Product line	PAN
Technology	LED
Variant	UGR<19
Body material	Metal
Diffuser / lens material	PC
Operating temperature (° C)	-20 - +40

### PACKAGING

Packaging	BOX
Pack	6
Gross weight (Kg)	17.5
Net weight (Kg)	2.07

ACCESSORIES		
	CONSTANT CURRENT LED DRIVER FOR LED PANEL	LD3PAND38
	CONSTANT CURRENT LED DRIVER FOR LED PANEL	LD3PAND42D
	CONSTANT CURRENT LED DRIVER FOR LED PANEL	MFD-1100-42-D
	SUSPENDED MOUNTING KIT	LD3PAN CAB
	UNIVERSAL CEILING MOUNTING KIT ASSEMBLY WITH SCREWS	LD2PANFRM-2
	UNIVERSAL SURFACE MOUNTING KIT	LD4PANFRM
	UNIVERSAL RECESSED MOUNTING KIT WITH FRAME	LD3PANINK
	RECESS MOUNTING KIT WITH SPRINGS	LD3PANSPG
	MULTIFUNCTIONAL EMERGENCY KIT	EMK5-90-15-A

LIGHTING DATA	
Kelvin (°)	4000
Lumen	3400
Beam (°)	90
Luminous Efficacy (lm / W)	89,47
Color rendering (CRI)	>90

TECHNICAL FEATURES	
Power (W)	38,0
Supply voltage (V) / Max (V)	220 / 240
Power frequency (Hz)	50/60
Current consumption (mA)	195
Insulation class	2
Power factor	>0,90
Dimmer compatibility	NO

## **600X600 LED PANEL WITH HIGH VISUAL COMFORT**

LD3PAN3853U9

38,0W - 3400lm - 4000K

- LED panel 10mm thick with side light source
- Engineered for highest viewing comfort: low glare UGR<19 and high chromatic rendering CRI>90
- Frame in aluminium with white paint finish RAL9016
- Front protection IP40 (rear IP20)
- Separate flicker-free driver with quick fit DC power connector
- Optional: KIT for surface mounting, suspension and recessed
- Optional: emergency KIT for easy assembly using DC power connectors

