



iM2075 Storm

The Peli™ Storm Case™ has the same legendary DNA as our Peli Protector Case, with one primary difference: A unique Press and Pull latch that locks automatically, but open with a light touch. Guaranteed for life, the Peli Storm case is made in the USA and engineered using the finest components.

- **Watertight, crushproof, and dustproof**

- Two Press & Pull Latches
- Two Padlockable Hasps
- Double-layered, Soft-grip Handle
- Vortex™ Valve
- Powerful Hinges
- Lightweight Strong HPX® Resin



CONFIGURATIONS



DIMENSIONS

Interior (L×W×D)	9.50 x 7.50" x 7.25 (24.1 x 19.1 x 18.4 cm)
Exterior (L×W×D)	11.80 x 9.80" x 7.70 (30 x 24.9 x 19.6 cm)
Lid Depth	1.50" (3.8 cm)
Bottom Depth	5.75" (14.6 cm)
Total Depth	7.25" (18.4 cm)
Int Volume	0.3 ft³ (0.008 m³)
Padlock Hole Diameter	0.28" (0.7 cm)

MATERIALS

Body	Injection Molded HPX™ high performance resin
Latch	Valox - Polybutylene Terephthalate (PBT)
Latch (Alt)	Xenoy - Polyester/Polycarbonate blend
O-Ring	EPDM
Pins	Stainless Steel
Pins (Alt)	Aluminum
Foam	1.3/1.35 polyester
Purge Body	Valox - Polybutylene Terephthalate (PBT)
Purge Body (Alt)	Xenoy - Polyester/Polycarbonate blend
Purge Vent	Gortex membrane

COLOURS

Black	OD Green	Yellow
-------	----------	--------

WEIGHT

Weight With Foam	3.70 lbs (1.68 kg)
Weight Empty	3.30 lbs (1.5 kg)
Buoyancy	18.20 lbs (8.26 kg)
Master Pack Weight	18.20 lbs (8.26 kg)

TEMPERATURE

Minimum Temperature	-20°F (-28.9 °C)
Maximum Temperature	140°F (60 °C)

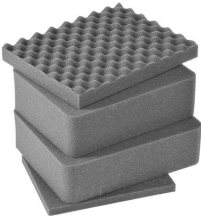
CERTIFICATIONS

IP67	
------	--

OTHER

Master Pack	4
Military	yes

ACCESSORIES

				
iM2075-FOAM 4 pc. Replacement Foam Set	iM-STRAP-S-VER2 Padded Shoulder Strap	iM-LIDSTAY Lid Stay	1506TSA TSA Lock	1500D Desiccant Silica Gel
				
iM20XX-M4-BEZEL Base Bezel Kit (Metric)				