


UM 45-FLK10


Order No.: 2962544

The illustration shows a 34-position version

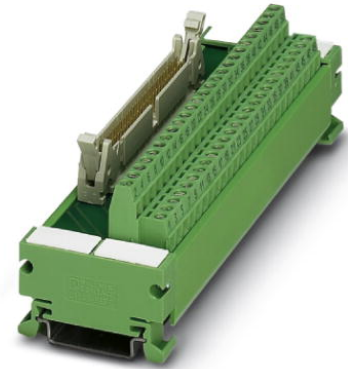


VARIOFACE module, with screw connection and flat-ribbon cable connector, for assembly on NS 35/7.5, 10 positions



Commercial data	
EAN	 4 017918 087210
Pack	1
Customs tariff	85369010
Gross weight in pieces	72.40 g
Country of Origin	DE
Catalog page information	Page 244 (IF-2007)

Product notes

WEEE/RoHS-compliant since:
14/07/2006



Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation at <http://www.download.phoenixcontact.com>. The General Terms and Conditions of Use apply to Internet downloads.

Technical data	
General data	
Nominal voltage U_N	25 V AC 60 V DC
Max. current carrying capacity per branch	1 A
Number of positions	10
Width	54 mm

Height	45 mm
Depth	50 mm
Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C
Test voltage input/output	500 V AC
Mounting position	Any
Standards/regulations	IEC 60664
	DIN EN 50178
	DIN VDE 110
Pollution degree	2
Surge voltage category	II

Connection data for connection 1

Connection name	PCB connection
Connection in acc. with standard	IEC / EN
Connection method	Screw connection
Conductor cross section solid min.	0.14 mm ²
Conductor cross section solid max.	1.5 mm ²
Conductor cross section stranded min.	0.14 mm ²
Conductor cross section stranded max.	1.5 mm ²
Conductor cross section AWG/kcmil min.	26
Conductor cross section AWG/kcmil max	16
Stripping length	6 mm
Screw thread	M3

Certificates



Certification

cULus Recognized, GOST

Certifications applied for:


Certification Ex:

Accessories

Item	Designation	Description
Cable/conductor		
2299204	FLK 10/EZ-DR/ 50/KONFEK	Round cable set, with two 10-pos. socket strips, (1:1 connection), cable length: 0.5 m
2299217	FLK 10/EZ-DR/ 100/KONFEK	Round cable set, with two 10-pos. socket strips (1:1 connection), cable length: 1 m
2299220	FLK 10/EZ-DR/ 150/KONFEK	Round cable set, with two 10-pos. socket strips (1:1 connection), cable length: 1.5 m
2299233	FLK 10/EZ-DR/ 200/KONFEK	Round cable set, with two 10-pos. socket strips, (1:1 connection), cable length: 2 m
2299246	FLK 10/EZ-DR/ 300/KONFEK	Round cable set, with two 10-pos. socket strips (1:1 connection), cable length: 3 m
2299259	FLK 10/EZ-DR/ 400/KONFEK	Round cable set, with two 10-pos. socket strips (1:1 connection), cable length: 4 m
2299262	FLK 10/EZ-DR/ 600/KONFEK	Round cable set, with two 10-pos. socket strips (1:1 connection), cable length: 6 m
2299275	FLK 10/EZ-DR/ 800/KONFEK	Round cable set, with two 10-pos. socket strips (1:1 connection), cable length: 8 m
2299288	FLK 10/EZ-DR/1000/KONFEK	Round cable set, with two 10-pos. socket strips (1:1 connection), cable length: 10 m
2295059	FLK EZ-DR.../.../...	Round cable, with preassembly, not shielded, variable cable length

Drawings

Circuit diagram

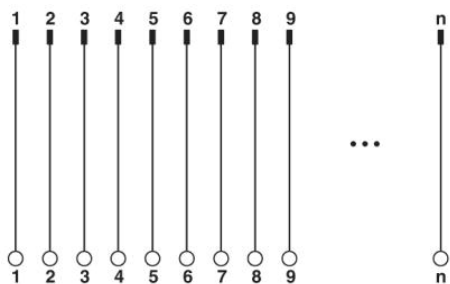

Address

PHOENIX CONTACT Ltd
Halesfield 13
Telford / Shropshire / TF7 4PG,England
Phone 01952 681 700
Fax 01952 681 799
<http://www.phoenixcontact.co.uk>



Phoenix Contact Ltd.
Technical modifications reserved;