


## Features

- **Dual-Function Design**  
– Combines secure key storage with visible permit-to-work display to enhance lockout/tagout safety compliance.
- **High Storage Capacity**  
– Accommodates up to 24 (12 x 2) padlocks via internal hook rails, supporting large teams during group lockouts.
- **Secure Locking Access** – Includes 20 insertion holes for personal padlocks and 3 additional holes for authorised personnel, ensuring controlled access.
- **Visible Work Permit Display** – Transparent polycarbonate front panel allows display of A4-sized documents for operational clarity.
- **Integrated Key Deposit Slot** – Enables secure key drop without opening the box, maintaining lockout integrity.
- **Wall-Mountable and Durable** – Made from powder-coated steel with stainless steel handle, includes wall-mount bracket for permanent installation.

## RS PRO Group Lockout Permit Box with Wall Bracket –24 Lock Capacity

RS Stock No.: 0710491

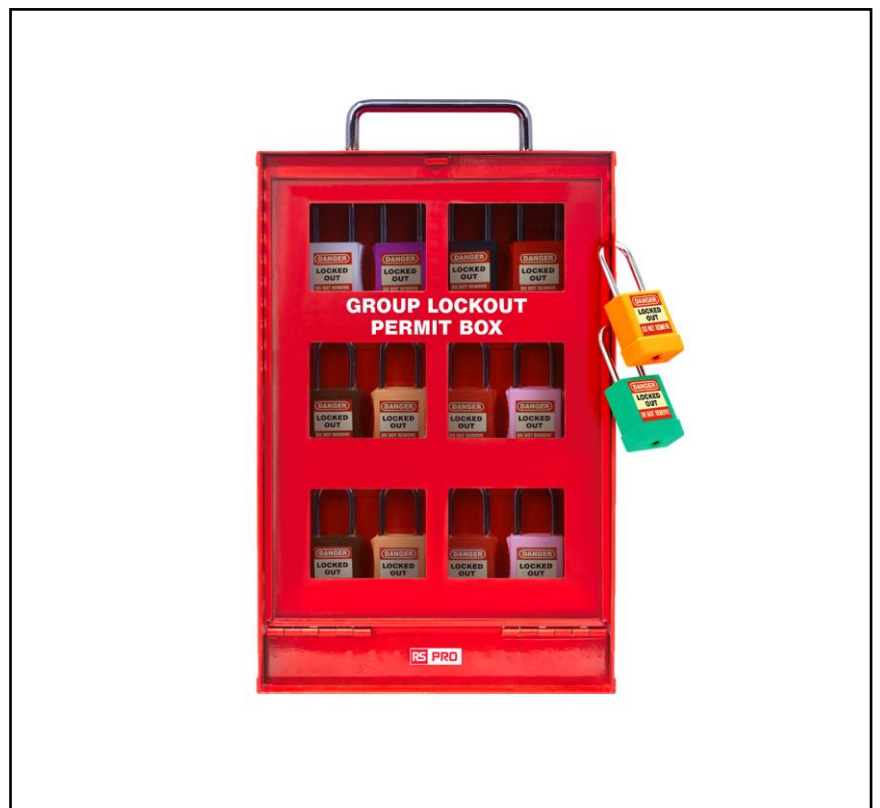

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

- *Premium Group Lockout Box ideal for maintenance and shutdown operations.*
- *Displays A4-sized permits through a clear, impact-resistant front panel.*
- *Internal hook rails hold up to 24 padlocks for team-based lockout procedures.*
- *20 holes for personal locks + 3 additional for supervisory access or special authorization.*
- *Integrated deposit slot allows keys to be added without reopening the box.*
- *Built from heavy-duty powder-coated steel with a stainless-steel carry handle.*
- *Wall-mountable with included bracket—ideal for centralized lockout stations.*
- *Locks the displayed permit until all personal locks are removed, increasing control and accountability.*

## General Specifications

<b>Type</b>	Group Lockout Box
<b>Material</b>	Powder-coated steel body and hook rails; clear polycarbonate front pane + 2 magnets
<b>Colour</b>	Red
<b>Package</b>	Corrugated box

## Mechanical Specifications

<b>Dimensions</b>	380mm (L) × 240mm (W) × 70mm (D)
<b>Length</b>	380mm
<b>Width</b>	240mm
<b>Depth</b>	70mm
<b>Max. Shackle Diameter</b>	7mm
<b>Capacity</b>	24 padlocks + A4 permit document
<b>Weight</b>	3.6 Kgs

## Operation Environment Specifications

<b>Withstand temperature</b>	-40°C to +100°C (-40°F to +212°F)
------------------------------	-----------------------------------