


SuperLine 2D



2-axis line laser –
Easy to operate with 360° rotatable
angle scale.

Rev. 1108

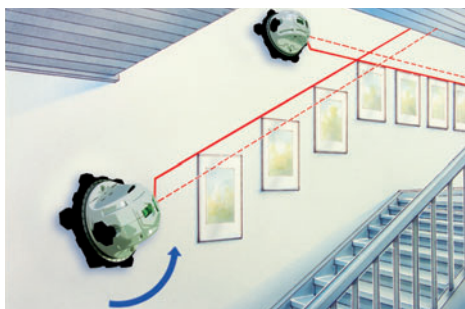

– Attach to carpets, painted walls, finishing coats, gypsum fibreboard, tiles, glass, wood, veneered surfaces, etc., **easily and without causing any damage.**

– **Aligning:** The rotatable angle scale means that the device and the graduated collar can be set separately to any angle.

– **Wall applications:** Attach base plate to wall using special pins – enables precise horizontal and vertical levelling.

Optional: Attachment also possible with adhesive strips – Laserliner ConTacts.

– **Floor applications:** Place the device and base plate on the floor – in this position, the device cannot be used as a spirit level.

– **Magnet attachment:** Powerful adhesion magnets facilitate attachment to magnetic surfaces.

– **Laser:** Bright

TECHNICAL DATA

ACCURACY 1 mm / 1 m

LASER WAVELENGTH 650 nm / ± 10 nm

LASER class 2 M, < 5 mW
(EN 60825-1:2005-10)

POWER SUPPLY
batteries 2 x type AAA

WEIGHT 0.2 kg

DIMENSIONS (W x H x D)
120 x 70 x 100 mm



magnetic



Service



Articel No: 081.110A

EAN-Code: 4 021563 662579


SuperLine 2D
+ batteries (2 x type AAA)

Packing dimension (W x H x D)
190 x 155 x 70 mm

PU 5

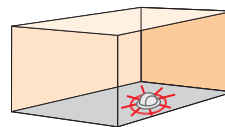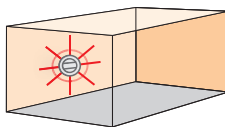

Attachment with pins

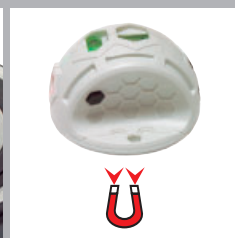

Magnetic



Optional adhesive strips

OPTIONAL ACCESSORIES

ARTICEL	ARTICEL NO	EAN-CODE	PU
Laser enhancement glasses/ideal visibility for laser marker	020.70A	4 011879 643980	1
ConTacts / 12 pieces	081.101A	4 021563 662883	1