



HIRSCHMANN

A Belden Brand

Product information GDME UV 3 N

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type A:Field Attachable Valve Connectors:Electronic inserts for GDME:GDME UV 3 N

<https://catalog.beldensolutions.com:443/link/57078-24228-256261-256266-256270-276215-24315-35720/en/conf/ui/state>

Name GDME UV 3 N

unequipped circuit board with 2 fork type springs and 2 flat head terminals

Delivery informations

Availability available

Product description

Description unequipped circuit board with 2 fork type springs and 2 flat head terminals

Type GDME UV 3 N

Order No. 931 954-001

Standard DIN EN 175 301-803-A

Construction type A

Technical data

Rated current 10 A

Environmental conditions


Temperature range -40 °C to +110 °C

Packing unit

Packaging unit 50 pieces

Picture

Drawing

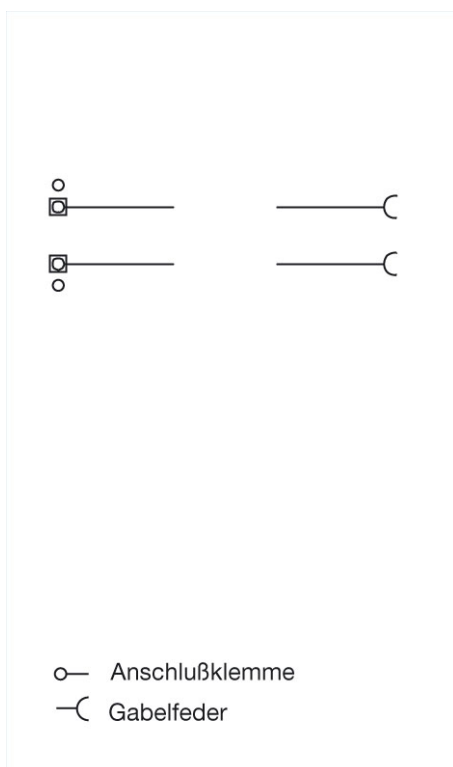



HIRSCHMANN

A **BELDEN** BRAND

Belden Deutschland GmbH

Im Gewerbepark 2

58579 Schalksmühle

Germany

Phone: +49 7127/14-1806

E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.