



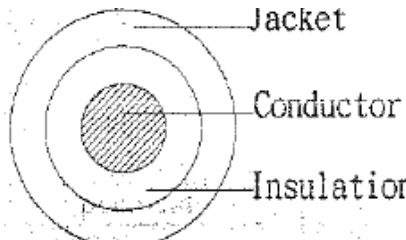

Datasheet

Product Name:	UL1385 26AWG
Product Discription:	UL1385 26AWG
Specification No.:	SPEC-UL1385-26AWG
Customer's Name:	

Description		Construction				
Rated Voltage:	No voltage rating	Conductor	Stranded Tinned Copper			
Rated Temperature:	125°C	Size(AWG)	26			
Reference Standard:	UL758	Construction(±0.004mm)	7/0.16			
Cross Section 		Stranded Dia.(mm)Ref.	0.49			
		Insulation Material	XL-PE		Jacket Material	XL-PVDF
		Insulation Color	White		Jacket Color	Any color
		Ave Thickness(mm)	0.15		Ave Thickness(mm)	0.10
		Min Thickness(mm)	0.12		Min Thickness(mm)	0.08
		Insulation Dia.(±0.10mm)	0.80		Jacket Dia.(±0.10mm)	1.00

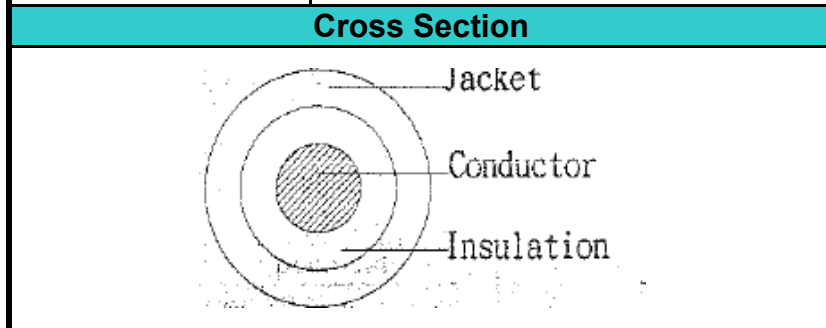

Marking

No cable marking

Remark:

8918704 Red	8918713 Blue	8918726 Grey	8918735 Violet
8918707 Black	8918716 White	8918729 Yellow	
8918700 Brown	8918710 Green	8918722 Orange	

Applications

Internal wiring of electronic equipment.

Characteristics		Customer Approve
Test Item	Standard Value	Seal & Stamp
Test Material	XLPE and XLPVDF(ROHS)	
Insulation resistance(20°C MΩ/KM)	0.75	
Vol. Tesr(AC.V.60S) (V)	500	
Flammability Test	Horizontal flame	
Max.DC Resistance(20°C Ω/km)	150(MAX)	

Revisions

Version	Description	Drawn by	Approved by	Date
0	New document issue	YanBin	Jason	10/08/2015

Signature:

Date: